


TOLERANZEN P

TOLERANCES P

P-Normplatte / P-standard plate

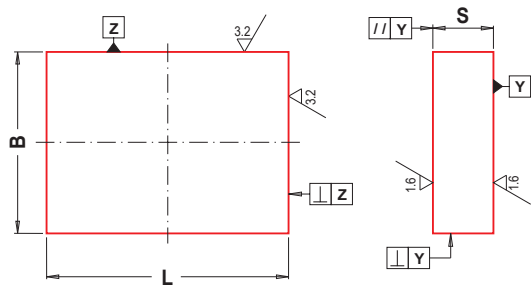


P..		B / L	P..
\parallel / Y	0,006 / 100		≤ 496
\perp / Y	0,04 / 100	≤ 996	+0,20 0
\perp / Z	0,04 / 100	> 996	+0,30 0

S	Mat.	B / L	P..
	1730 2085 2311 2312 2714HH 2738 2738TSHH 3.4365	≤ 496	+0,25 +0,20
	≤ 1196	+0,35 +0,30	
2083 2162 2343 2343ESU 2379 2767	≤ 246	+0,45 +0,40	
	≤ 346	+0,55 +0,50	
	≤ 1196	+0,65 +0,60	

Standardisierte Maße für bearbeitete Platten ~ DIN 16760 / Standardized dimensions for machined plates


PL-Normleiste / PL-standard riser

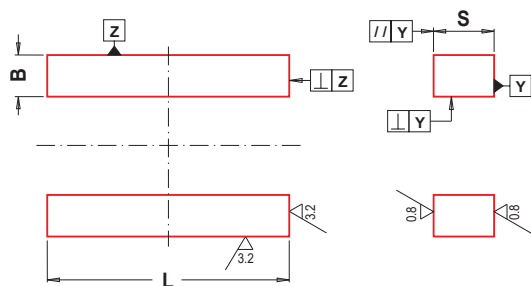

P..		B / L	P..
\parallel / Y	0,006 / 300		≤ 496
\perp / Y	0,04 / 100	≤ 996	+0,20 0
\perp / Z	0,04 / 100	> 996	+0,30 0

S	P..
	+0,02 0

PR-Rundplatte / PR-Round plate

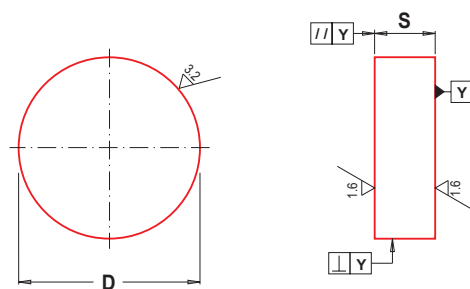

PR..		Ø	PR..
\parallel / Y	0,006 / 100		≤ 500
\perp / Y	0,04 / 100	≤ 1000	+0,20 0
		> 1000	+0,30 0

S	Ø	PR..
	≤ 500	+0,25 +0,20
≤ 1200	+0,35 +0,30	