




 






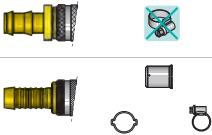
 





 


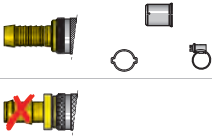

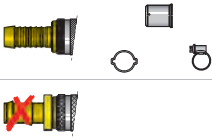
 



 




 


 














TEMPERIERSCHLÄUCHE ÜBERSICHT OVERVIEW: COOLANT HOSES

Schlauch Hose	Medium Medium	Temp. Temp.	Druck Pressure	Montage Installation	Beschreibung Description
E 2180 	 Water  Air  Steam	140°C	20 bar		Temperierschlauch, EPDM EPDM coolant hose
E 2182 	 Water  Air	60°C	12 bar		Temperierschlauch, PVC PVC coolant hose
E 2185 	 Water  Air	140°C	28 bar		Schnellsteck-Temperierschlauch Quick-fit coolant hose
E 2187  IsoTemp®	 Water  Oil  Air  Steam	200°C	60 bar		IsoTemp® Hochtemperaturschlauch IsoTemp® high temperature hose
E 21872 	 Water  Oil  Air  Steam	200°C	60 bar		Hochtemperaturschlauch High temperature hose
E 7450 	 Water  Oil  Air	90°C	6 - 16 bar		Kunststoffschlauch PU-H plus Flexible plastic tubing PU-H plus
E 7451 	 Water  Oil  Air	60°C	6 - 14 bar		Kunststoffschlauch PU-H Flexible plastic tubing PU-H

WERKZEUGE TOOLS

V 20420 	E 21990 	E 2196 	E 2198 	V 34000 
				
				
		E 2190	E 2192	E 2194