

E 1012 DLC




**Führungssäule ohne Zentrierbund,
ohne Schmiernuten, DLC - beschichtet**

*Guide pillar without centring collar,
without oil grooves, DLC coated*

» Zwei Passdurchmesser für einfache
Montage und festen Sitz

» *Two fitting diameters for easy
installation and a tight fit*

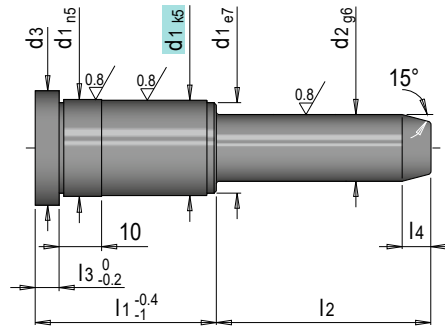

**DLC beschichtet
coated**

Mat.: 1.7131 ≈ 60 HRC

l3	l4	d3	d1	d2	l1	l2	Nr. / No.	d2	Nr. / No.	l3	l4	d3	d1	d2	l1	l2	Nr. / No.	d2	Nr. / No.				
6	5	25	20	14	22	35	E 1012 DLC/14 - 22/ 35	15	E 1012 DLC/15 - 22/ 35	6	7	35	30	22	56	155	E 1012 DLC/22 - 56/155	24	E 1012 DLC/24 - 56/155				
						55	E 1012 DLC/14 - 22/ 55		E 1012 DLC/15 - 22/ 55					66	55	E 1012 DLC/22 - 66/ 55			E 1012 DLC/24 - 66/ 55				
						75	E 1012 DLC/14 - 22/ 75		E 1012 DLC/15 - 22/ 75					75	55	E 1012 DLC/22 - 66/ 75			E 1012 DLC/24 - 66/ 75				
						95	E 1012 DLC/14 - 22/ 95		E 1012 DLC/15 - 22/ 95					95	55	E 1012 DLC/22 - 66/ 95			E 1012 DLC/24 - 66/ 95				
					27	35	E 1012 DLC/14 - 27/ 35		E 1012 DLC/15 - 27/ 35					115	55	E 1012 DLC/22 - 66/115			E 1012 DLC/24 - 66/115				
						55	E 1012 DLC/14 - 27/ 55		E 1012 DLC/15 - 27/ 55					76	55	E 1012 DLC/22 - 76/ 55			E 1012 DLC/24 - 76/ 55				
						75	E 1012 DLC/14 - 27/ 75		E 1012 DLC/15 - 27/ 75					75	55	E 1012 DLC/22 - 76/ 75			E 1012 DLC/24 - 76/ 75				
						95	E 1012 DLC/14 - 27/ 95		E 1012 DLC/15 - 27/ 95					95	55	E 1012 DLC/22 - 76/ 95			E 1012 DLC/24 - 76/ 95				
					36	35	E 1012 DLC/14 - 36/ 35		E 1012 DLC/15 - 36/ 35					115	55	E 1012 DLC/22 - 76/115			E 1012 DLC/24 - 76/115				
						55	E 1012 DLC/14 - 36/ 55		E 1012 DLC/15 - 36/ 55					86	75	E 1012 DLC/22 - 86/ 75			E 1012 DLC/24 - 86/ 75				
						75	E 1012 DLC/14 - 36/ 75		E 1012 DLC/15 - 36/ 75					95	55	E 1012 DLC/22 - 86/ 95			E 1012 DLC/24 - 86/ 95				
						95	E 1012 DLC/14 - 36/ 95		E 1012 DLC/15 - 36/ 95					96	75	E 1012 DLC/22 - 96/ 75			E 1012 DLC/24 - 96/ 75				
					46	35	E 1012 DLC/14 - 46/ 35		E 1012 DLC/15 - 46/ 35					95	55	E 1012 DLC/22 - 96/ 95			E 1012 DLC/24 - 96/ 95				
						55	E 1012 DLC/14 - 46/ 55		E 1012 DLC/15 - 46/ 55					6	7	47	42	30	46	55	E 1012 DLC/30 - 46/ 55	32	E 1012 DLC/32 - 46/ 55
						75	E 1012 DLC/14 - 46/ 75		E 1012 DLC/15 - 46/ 75					75	55	E 1012 DLC/30 - 46/ 75			E 1012 DLC/32 - 46/ 75				
						56	E 1012 DLC/14 - 56/ 55		E 1012 DLC/15 - 56/ 55					95	55	E 1012 DLC/30 - 46/ 95			E 1012 DLC/32 - 46/ 95				
						75	E 1012 DLC/14 - 56/ 75		E 1012 DLC/15 - 56/ 75					115	55	E 1012 DLC/30 - 46/115			E 1012 DLC/32 - 46/115				
						66	E 1012 DLC/14 - 66/ 55		E 1012 DLC/15 - 66/ 55					155	55	E 1012 DLC/30 - 46/155			E 1012 DLC/32 - 46/155				
						75	E 1012 DLC/14 - 66/ 75		E 1012 DLC/15 - 66/ 75					195	55	E 1012 DLC/30 - 46/195			E 1012 DLC/32 - 46/195				
					6	7	31	26	18	27	35	E 1012 DLC/18 - 27/ 35	20	E 1012 DLC/20 - 27/ 35			56	55	E 1012 DLC/30 - 56/ 55			E 1012 DLC/32 - 56/ 55	
						55	E 1012 DLC/18 - 27/ 55		E 1012 DLC/20 - 27/ 55					55	55	E 1012 DLC/30 - 56/ 75			E 1012 DLC/32 - 56/ 75				
						75	E 1012 DLC/18 - 27/ 75		E 1012 DLC/20 - 27/ 75					95	55	E 1012 DLC/30 - 56/ 95			E 1012 DLC/32 - 56/ 95				
						95	E 1012 DLC/18 - 27/ 95		E 1012 DLC/20 - 27/ 95					115	55	E 1012 DLC/30 - 56/115			E 1012 DLC/32 - 56/115				
						115	E 1012 DLC/18 - 27/115		E 1012 DLC/20 - 27/115					155	55	E 1012 DLC/30 - 56/155			E 1012 DLC/32 - 56/155				
						155	E 1012 DLC/18 - 27/155		E 1012 DLC/20 - 27/155					66	55	E 1012 DLC/30 - 66/ 55			E 1012 DLC/32 - 66/ 55				
						36	E 1012 DLC/18 - 36/ 35		E 1012 DLC/20 - 36/ 35					75	55	E 1012 DLC/30 - 66/ 75			E 1012 DLC/32 - 66/ 75				
						55	E 1012 DLC/18 - 36/ 55		E 1012 DLC/20 - 36/ 55					95	55	E 1012 DLC/30 - 66/ 95			E 1012 DLC/32 - 66/ 95				
						75	E 1012 DLC/18 - 36/ 75		E 1012 DLC/20 - 36/ 75					115	55	E 1012 DLC/30 - 66/115			E 1012 DLC/32 - 66/115				
						95	E 1012 DLC/18 - 36/ 95		E 1012 DLC/20 - 36/ 95					155	55	E 1012 DLC/30 - 66/155			E 1012 DLC/32 - 66/155				
						115	E 1012 DLC/18 - 36/115		E 1012 DLC/20 - 36/115					76	55	E 1012 DLC/30 - 76/ 55			E 1012 DLC/32 - 76/ 55				
						155	E 1012 DLC/18 - 36/155		E 1012 DLC/20 - 36/155					75	55	E 1012 DLC/30 - 76/ 75			E 1012 DLC/32 - 76/ 75				
						46	E 1012 DLC/18 - 46/ 35		E 1012 DLC/20 - 46/ 35					95	55	E 1012 DLC/30 - 76/ 95			E 1012 DLC/32 - 76/ 95				
						55	E 1012 DLC/18 - 46/ 55		E 1012 DLC/20 - 46/ 55					115	55	E 1012 DLC/30 - 76/115			E 1012 DLC/32 - 76/115				
						75	E 1012 DLC/18 - 46/ 75		E 1012 DLC/20 - 46/ 75					155	55	E 1012 DLC/30 - 76/155			E 1012 DLC/32 - 76/155				
						95	E 1012 DLC/18 - 46/ 95		E 1012 DLC/20 - 46/ 95					86	75	E 1012 DLC/30 - 86/ 75			E 1012 DLC/32 - 86/ 75				
						56	E 1012 DLC/18 - 56/ 55		E 1012 DLC/20 - 56/ 55					95	55	E 1012 DLC/30 - 86/ 95			E 1012 DLC/32 - 86/ 95				
						75	E 1012 DLC/18 - 56/ 75		E 1012 DLC/20 - 56/ 75					115	55	E 1012 DLC/30 - 86/115			E 1012 DLC/32 - 86/115				
						95	E 1012 DLC/18 - 56/ 95		E 1012 DLC/20 - 56/ 95					155	55	E 1012 DLC/30 - 86/155			E 1012 DLC/32 - 86/155				
						66	E 1012 DLC/18 - 66/ 55		E 1012 DLC/20 - 66/ 55					96	75	E 1012 DLC/30 - 96/ 75			E 1012 DLC/32 - 96/ 75				
						75	E 1012 DLC/18 - 66/ 75		E 1012 DLC/20 - 66/ 75					95	55	E 1012 DLC/30 - 96/ 95			E 1012 DLC/32 - 96/ 95				
						95	E 1012 DLC/18 - 66/ 95		E 1012 DLC/20 - 66/ 95					115	55	E 1012 DLC/30 - 96/115			E 1012 DLC/32 - 96/115				
						76	E 1012 DLC/18 - 76/ 55		E 1012 DLC/20 - 76/ 55					155	55	E 1012 DLC/30 - 96/155			E 1012 DLC/32 - 96/155				
						55	E 1012 DLC/18 - 76/ 75		E 1012 DLC/20 - 76/ 75					116	75	E 1012 DLC/30 - 116/ 75			E 1012 DLC/32 - 116/ 75				
						75	E 1012 DLC/18 - 76/ 95		E 1012 DLC/20 - 76/ 95					115	55	E 1012 DLC/30 - 116/115			E 1012 DLC/32 - 116/115				
						35	E 1012 DLC/22 - 36/ 35	24	E 1012 DLC/24 - 36/ 35					155	55	E 1012 DLC/30 - 116/155			E 1012 DLC/32 - 116/155				
						55	E 1012 DLC/22 - 36/ 55		E 1012 DLC/24 - 36/ 55					136	95	E 1012 DLC/30 - 136/ 95			E 1012 DLC/32 - 136/ 95				
						75	E 1012 DLC/22 - 36/ 75		E 1012 DLC/24 - 36/ 75					115	55	E 1012 DLC/30 - 136/115			E 1012 DLC/32 - 136/115				
						95	E 1012 DLC/22 - 36/ 95		E 1012 DLC/24 - 36/ 95					155	55	E 1012 DLC/30 - 136/155			E 1012 DLC/32 - 136/155				
						115	E 1012 DLC/22 - 36/115		E 1012 DLC/24 - 36/115					156	115	E 1012 DLC/30 - 156/115			E 1012 DLC/32 - 156/115				
						155	E 1012 DLC/22 - 36/155		E 1012 DLC/24 - 36/155					155	55	E 1012 DLC/30 - 156/155			E 1012 DLC/32 - 156/155				
						195	E 1012 DLC/22 - 36/195		E 1012 DLC/24 - 36/195					10	10	59	54	40	96	75	E 1012 DLC/40 - 96/ 75	42	E 1012 DLC/42 - 96/ 75
						235	E 1012 DLC/22 - 36/235		E 1012 DLC/24 - 36/235					95	55	E 1012 DLC/40 - 96/ 95			E 1012 DLC/42 - 96/ 95				
						46	E 1012 DLC/22 - 46/ 35		E 1012 DLC/24 - 46/ 35					115	55	E 1012 DLC/40 - 96/115			E 1012 DLC/42 - 96/115				
						35	E 1012 DLC/22 - 46/ 55		E 1012 DLC/24 - 46/ 55					116	55	E 1012 DLC/40 - 116/115			E 1012 DLC/42 - 116/115				
						75	E 1012 DLC/22 - 46/ 75		E 1012 DLC/24 - 46/ 75					155	55	E 1012 DLC/40 - 116/155			E 1012 DLC/42 - 116/155				
						95	E 1012 DLC/22 - 46/ 95		E 1012 DLC/24 - 46/ 95					136	115	E 1012 DLC/40 - 136/115			E 1012 DLC/42 - 136/115				
						115	E 1012 DLC/22 - 46/115		E 1012 DLC/24 - 46/115					155	55	E 1012 DLC/40 - 136/155			E 1012 DLC/42 - 136/155				
						155	E 1012 DLC/22 - 46/155		E 1012 DLC/24 - 46/155					156	55	E 1012 DLC/40 - 156/155			E 1012 DLC/42 - 156/155				
						195	E 1012 DLC/22 - 46/195		E 1012 DLC/24 - 46/195					195	55	E 1012 DLC/40 - 156/195			E 1012 DLC/42 - 156/195				
						235	E 1012 DLC/22 - 46/235		E 1012 DLC/24 - 46/235					196	115	E 1012 DLC/40 - 196/115			E 1012 DLC/42 - 196/115				
						56	E 1012 DLC/22 - 56/ 55		E 1012 DLC/24 - 56/														