

## E 1105




### Führungsbuchse mit Zentrierbund wartungsfrei

Guide bush with centring collar, self lubricating

» Graphiteinsätze für lebenslange Schmierung

» Graphite inserts for permanent lubrication

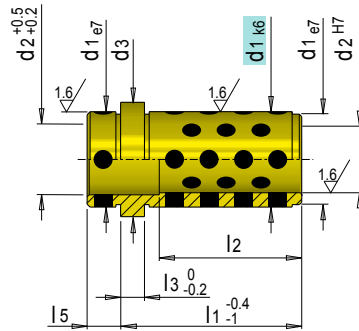

Mat.: 2.0598

≈ 200 HB / Graphit / graphite

t max. = 200°C

l2 <sup>1)</sup>	l3	l5	d3	d1	d2	l1	Nr. / No.	d2	Nr. / No.
-	3	3	16	14	9	12	E 1105/ 9 - 12	10	E 1105/10 - 12
						17	E 1105/ 9 - 17		E 1105/10 - 17
						22	E 1105/ 9 - 22		E 1105/10 - 22
						27	E 1105/ 9 - 27		E 1105/10 - 27
						36	E 1105/ 9 - 36		E 1105/10 - 36
22						46	E 1105/ 9 - 46		E 1105/10 - 46
						56	E 1105/ 9 - 56		E 1105/10 - 56
-	6	6	25	20	14	17	E 1105/14 - 17	15	E 1105/15 - 17
						22	E 1105/14 - 22		E 1105/15 - 22
						27	E 1105/14 - 27		E 1105/15 - 27
						36	E 1105/14 - 36		E 1105/15 - 36
30						46	E 1105/14 - 46		E 1105/15 - 46
						56	E 1105/14 - 56		E 1105/15 - 56
						66	E 1105/14 - 66		E 1105/15 - 66
						76	E 1105/14 - 76		E 1105/15 - 76
-	6	8	31	26	18	17	E 1105/18 - 17	20	E 1105/20 - 17
						22	E 1105/18 - 22		E 1105/20 - 22
						27	E 1105/18 - 27		E 1105/20 - 27
						36	E 1105/18 - 36		E 1105/20 - 36
40						46	E 1105/18 - 46		E 1105/20 - 46
						56	E 1105/18 - 56		E 1105/20 - 56
						66	E 1105/18 - 66		E 1105/20 - 66
						76	E 1105/18 - 76		E 1105/20 - 76
						86	E 1105/18 - 86		E 1105/20 - 86
						96	E 1105/18 - 96		E 1105/20 - 96
-	6	8	35	30	22	22	E 1105/22 - 22	24	E 1105/24 - 22
						27	E 1105/22 - 27		E 1105/24 - 27
						36	E 1105/22 - 36		E 1105/24 - 36
48						46	E 1105/22 - 46		E 1105/24 - 46
						56	E 1105/22 - 56		E 1105/24 - 56
						66	E 1105/22 - 66		E 1105/24 - 66
						76	E 1105/22 - 76		E 1105/24 - 76
						86	E 1105/22 - 86		E 1105/24 - 86
						96	E 1105/22 - 96		E 1105/24 - 96
						116	E 1105/22 - 116		E 1105/24 - 116
-	6	8	47	42	30	27	E 1105/30 - 27	32	E 1105/32 - 27
						36	E 1105/30 - 36		E 1105/32 - 36
						46	E 1105/30 - 46		E 1105/32 - 46
						56	E 1105/30 - 56		E 1105/32 - 56
64						66	E 1105/30 - 66		E 1105/32 - 66
						76	E 1105/30 - 76		E 1105/32 - 76
						86	E 1105/30 - 86		E 1105/32 - 86
						96	E 1105/30 - 96		E 1105/32 - 96
						116	E 1105/30 - 116		E 1105/32 - 116
						136	E 1105/30 - 136		E 1105/32 - 136
						156	E 1105/30 - 156		E 1105/32 - 156
-	10	10	59	54	40	36	E 1105/40 - 36	42	E 1105/42 - 36
						46	E 1105/40 - 46		E 1105/42 - 46
						56	E 1105/40 - 56		E 1105/42 - 56
						66	E 1105/40 - 66		E 1105/42 - 66
						76	E 1105/40 - 76		E 1105/42 - 76
84						86	E 1105/40 - 86		E 1105/42 - 86
						96	E 1105/40 - 96		E 1105/42 - 96
						116	E 1105/40 - 116		E 1105/42 - 116
						136	E 1105/40 - 136		E 1105/42 - 136
						156	E 1105/40 - 156		E 1105/42 - 156
						176	E 1105/40 - 176		E 1105/42 - 176
						196	E 1105/40 - 196		E 1105/42 - 196
						216	E 1105/40 - 216		E 1105/42 - 216
						236	E 1105/40 - 236		E 1105/42 - 236
						256	E 1105/40 - 256		E 1105/42 - 256

l2 <sup>1)</sup>	l3	l5	d3	d1	d2	l1	Nr. / No.	d2	Nr. / No.
-	10	10	71	66	50	56	E 1105/50 - 56	52	E 1105/52 - 56
						66	E 1105/50 - 66		E 1105/52 - 66
						76	E 1105/50 - 76		E 1105/52 - 76
						86	E 1105/50 - 86		E 1105/52 - 86
						96	E 1105/50 - 96		E 1105/52 - 96
104						116	E 1105/50 - 116		E 1105/52 - 116
						136	E 1105/50 - 136		E 1105/52 - 136
						156	E 1105/50 - 156		E 1105/52 - 156
						176	E 1105/50 - 176		E 1105/52 - 176
						196	E 1105/50 - 196		E 1105/52 - 196
						216	E 1105/50 - 216		E 1105/52 - 216
						236	E 1105/50 - 236		E 1105/52 - 236
						256	E 1105/50 - 256		E 1105/52 - 256

1) l2: Ist keine Angabe für l2 (-) in der Tabelle vorhanden, gilt d2 H7 über die gesamte Buchsenlänge. / l2: If there is no specification for l2 (-) in the table, d2 H7 applies to the entire bush length of the guide bush.

**i** Initialschmierung mit VGM 160  
Initial lubrication with VGM 160