

E 1127




Führungsbuchse wartungsfrei

Guide bush, self lubricating

» Graphiteinsätze für lebenslange Schmierung

» Graphite inserts for permanent lubrication

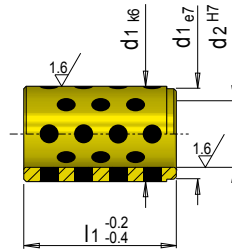

Mat.: 2.0598

≈ 200 HB / Graphit / graphite

t max. = 200°C

d2	d1	l1	Nr. / No.
9	14	8	E 1127/ 9/14/ 8
		12	E 1127/ 9/14/12
		16	E 1127/ 9/14/16
10	14	8	E 1127/10/14/ 8
		12	E 1127/10/14/12
		16	E 1127/10/14/16
12	16	12	E 1127/12/16/12
		16	E 1127/12/16/16
		20	E 1127/12/16/20
14	20	12	E 1127/14/20/12
		16	E 1127/14/20/16
		20	E 1127/14/20/20
15	20	12	E 1127/15/20/12
		20	E 1127/15/20/20
		20	E 1127/15/20/20
16	22	16	E 1127/16/22/16
		20	E 1127/16/22/20
		25	E 1127/16/22/25
18	26	16	E 1127/18/26/16
		20	E 1127/18/26/20
		25	E 1127/18/26/25
		32	E 1127/18/26/32
20	26	16	E 1127/20/26/16
		20	E 1127/20/26/20
		25	E 1127/20/26/25
		32	E 1127/20/26/32
22	30	20	E 1127/22/30/20
		25	E 1127/22/30/25
		32	E 1127/22/30/32
		40	E 1127/22/30/40
24	30	20	E 1127/24/30/20
		25	E 1127/24/30/25
		32	E 1127/24/30/32
		40	E 1127/24/30/40
30	42	25	E 1127/30/42/25
		32	E 1127/30/42/32
		40	E 1127/30/42/40
		50	E 1127/30/42/50
32	42	25	E 1127/32/42/25
		32	E 1127/32/42/32
		40	E 1127/32/42/40
		50	E 1127/32/42/50

i Initialschmierung mit VGM 160
Initial lubrication with VGM 160