


E 1230



Gewindestift mit Innensechskant

Hex-socket set screw

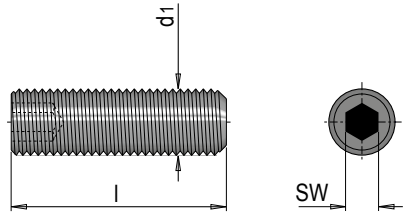

45H ISO 4026 (DIN 913)

SW	d1	l	Nr. / No.
1.5	M 3	3	E 1230/ 3 x 3
		4	E 1230/ 3 x 4
		5	E 1230/ 3 x 5
		6	E 1230/ 3 x 6
		8	E 1230/ 3 x 8
		10	E 1230/ 3 x 10
		12	E 1230/ 3 x 12
2	M 4	4	E 1230/ 4 x 4
		5	E 1230/ 4 x 5
		6	E 1230/ 4 x 6
		8	E 1230/ 4 x 8
		10	E 1230/ 4 x 10
		12	E 1230/ 4 x 12
		16	E 1230/ 4 x 16
2.5	M 5	6	E 1230/ 5 x 6
		8	E 1230/ 5 x 8
		10	E 1230/ 5 x 10
		12	E 1230/ 5 x 12
		16	E 1230/ 5 x 16
		20	E 1230/ 5 x 20
		25	E 1230/ 5 x 25
3	M 6	6	E 1230/ 6 x 6
		8	E 1230/ 6 x 8
		10	E 1230/ 6 x 10
		12	E 1230/ 6 x 12
		16	E 1230/ 6 x 16
		20	E 1230/ 6 x 20
		25	E 1230/ 6 x 25
4	M 8	8	E 1230/ 8 x 8
		10	E 1230/ 8 x 10
		12	E 1230/ 8 x 12
		16	E 1230/ 8 x 16
		20	E 1230/ 8 x 20
		25	E 1230/ 8 x 25
		30	E 1230/ 8 x 30
5	M10	10	E 1230/10 x 10
		12	E 1230/10 x 12
		16	E 1230/10 x 16
		20	E 1230/10 x 20
		25	E 1230/10 x 25
		30	E 1230/10 x 30
		35	E 1230/10 x 35
		40	E 1230/10 x 40
		45	E 1230/10 x 45
		55	E 1230/10 x 55
		60	E 1230/10 x 60
6	M12	12	E 1230/12 x 12
		16	E 1230/12 x 16
		20	E 1230/12 x 20
		25	E 1230/12 x 25
		30	E 1230/12 x 30
		40	E 1230/12 x 40
		50	E 1230/12 x 50
8	M16	16	E 1230/16 x 16
		20	E 1230/16 x 20
		25	E 1230/16 x 25
		30	E 1230/16 x 30

SW	d1	l	Nr. / No.
8	M16	40	E 1230/16 x 40
		50	E 1230/16 x 50
		60	E 1230/16 x 60
10	M20	20	E 1230/20 x 20
		30	E 1230/20 x 30
		40	E 1230/20 x 40
		50	E 1230/20 x 50
		60	E 1230/20 x 60
12	M24	25	E 1230/24 x 25
		40	E 1230/24 x 40
		60	E 1230/24 x 60
		80	E 1230/24 x 80