


E 1240



Schulterpassschraube

Shoulder screw

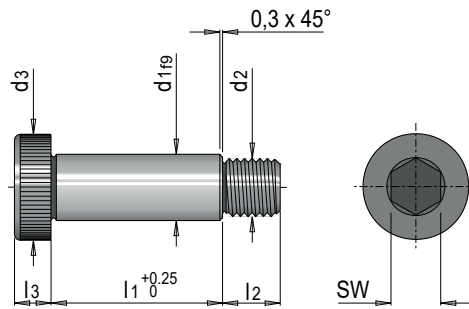

12.9 ISO 7379

SW	l3	l2	d3	d2	d1	l1	Nr. / No.
2.5	4	8	9	M 4	5	8	E 1240/ 5 x 8
						10	E 1240/ 5 x 10
						12	E 1240/ 5 x 12
						16	E 1240/ 5 x 16
						20	E 1240/ 5 x 20
						25	E 1240/ 5 x 25
						30	E 1240/ 5 x 30
						40	E 1240/ 5 x 40
3	4.5	9.5	10	M 5	6	8	E 1240/ 6 x 8
						10	E 1240/ 6 x 10
						12	E 1240/ 6 x 12
						16	E 1240/ 6 x 16
						20	E 1240/ 6 x 20
						25	E 1240/ 6 x 25
						30	E 1240/ 6 x 30
						35	E 1240/ 6 x 35
						40	E 1240/ 6 x 40
						45	E 1240/ 6 x 45
						50	E 1240/ 6 x 50
						55	E 1240/ 6 x 55
4	5.5	11	13	M 6	8	8	E 1240/ 8 x 8
						10	E 1240/ 8 x 10
						12	E 1240/ 8 x 12
						16	E 1240/ 8 x 16
						20	E 1240/ 8 x 20
						25	E 1240/ 8 x 25
						30	E 1240/ 8 x 30
						35	E 1240/ 8 x 35
						40	E 1240/ 8 x 40
						45	E 1240/ 8 x 45
						50	E 1240/ 8 x 50
						55	E 1240/ 8 x 55
						60	E 1240/ 8 x 60
						65	E 1240/ 8 x 65
70	E 1240/ 8 x 70						
80	E 1240/ 8 x 80						
90	E 1240/ 8 x 90						
100	E 1240/ 8 x 100						
5	7	13	16	M 8	10	10	E 1240/10 x 10
						12	E 1240/10 x 12
						16	E 1240/10 x 16
						20	E 1240/10 x 20
						25	E 1240/10 x 25
						30	E 1240/10 x 30
						35	E 1240/10 x 35
						40	E 1240/10 x 40
						45	E 1240/10 x 45
						50	E 1240/10 x 50
						55	E 1240/10 x 55
						60	E 1240/10 x 60
						65	E 1240/10 x 65
						70	E 1240/10 x 70
80	E 1240/10 x 80						
90	E 1240/10 x 90						
100	E 1240/10 x 100						
6	9	16	18	M10	12	12	E 1240/12 x 12
						16	E 1240/12 x 16

SW	l3	l2	d3	d2	d1	l1	Nr. / No.
6	9	16	18	M10	12	20	E 1240/12 x 20
						25	E 1240/12 x 25
						30	E 1240/12 x 30
						35	E 1240/12 x 35
						40	E 1240/12 x 40
						45	E 1240/12 x 45
						50	E 1240/12 x 50
						55	E 1240/12 x 55
						60	E 1240/12 x 60
						65	E 1240/12 x 65
						70	E 1240/12 x 70
						80	E 1240/12 x 80
8	11	18	24	M12	16	20	E 1240/16 x 20
						25	E 1240/16 x 25
						30	E 1240/16 x 30
						35	E 1240/16 x 35
						40	E 1240/16 x 40
						45	E 1240/16 x 45
						50	E 1240/16 x 50
						55	E 1240/16 x 55
						60	E 1240/16 x 60
						65	E 1240/16 x 65
						70	E 1240/16 x 70
						80	E 1240/16 x 80
90	E 1240/16 x 90						
100	E 1240/16 x 100						
110	E 1240/16 x 110						
120	E 1240/16 x 120						
10	14	22	30	M16	20	30	E 1240/20 x 30
						35	E 1240/20 x 35
						40	E 1240/20 x 40
						45	E 1240/20 x 45
						50	E 1240/20 x 50
						55	E 1240/20 x 55
						60	E 1240/20 x 60
						65	E 1240/20 x 65
						70	E 1240/20 x 70
						80	E 1240/20 x 80
						90	E 1240/20 x 90
						100	E 1240/20 x 100
110	E 1240/20 x 110						
120	E 1240/20 x 120						
12	16	27	36	M20	24	45	E 1240/24 x 45
						50	E 1240/24 x 50
						55	E 1240/24 x 55
						60	E 1240/24 x 60
						65	E 1240/24 x 65
						70	E 1240/24 x 70
						80	E 1240/24 x 80
						90	E 1240/24 x 90
						100	E 1240/24 x 100
						120	E 1240/24 x 120
						140	E 1240/24 x 140