


E 1251



Druckstück mit Gewindesicherung

Thrust piece with thread lock

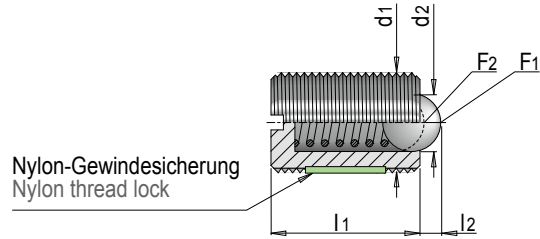

Mat.: 1.0715

t max. = 80°C

| F1 [N] | F2 [N] | l1 | l2 | d2 | d1 | Nr. / No. |
|--------|--------|----|-----|-----|------------|-----------|
| 1.5 | 3 | 7 | 0.4 | 1.5 | M 3 | E 1251/ 3 |
| 4 | 10 | 9 | 0.8 | 2.5 | M 4 | E 1251/ 4 |
| 6 | 11 | 12 | 0.9 | 3 | M 5 | E 1251/ 5 |
| 9 | 13 | 14 | 1 | 3.5 | M 6 | E 1251/ 6 |
| 15 | 30 | 16 | 1.5 | 5 | M 8 | E 1251/ 8 |
| 20 | 35 | 19 | 2 | 6 | M10 | E 1251/10 |
| 30 | 55 | 22 | 2.5 | 8 | M12 | E 1251/12 |
| 65 | 125 | 24 | 3.5 | 10 | M16 | E 1251/16 |