


E 1252



Druckstück mit verstärkter Federkraft

Thrust piece with higher spring force

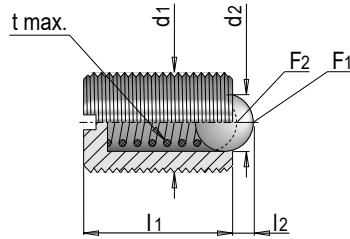

Mat.: 1.0715

t max. = 350°C

F1 [N]	F2 [N]	l1	l2	d2	d1	Nr. / No.
5	7	7	0.5	1.5	M 3	E 1252/ 3
12	22	9	0.8	2.5	M 4	E 1252/ 4
19	30	12	0.9	3	M 5	E 1252/ 5
28	40	14	1	3.5	M 6	E 1252/ 6
47	73	16	1.5	5	M 8	E 1252/ 8
66	100	19	2	6	M10	E 1252/10
66	120	22	2.5	8	M12	E 1252/12
90	180	24	3.5	10	M16	E 1252/16
115	240	30	4.5	12	M20	E 1252/20