


E 1254



Druckstück zylindrisch

Thrust piece, cylindrical end

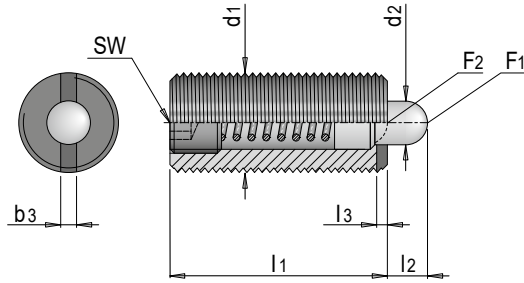

Mat.: 1.0715

t max. = 250°C

F1 [N]	F2 [N]	SW	l1	l2	d2	l3	b3	d1	Nr. / No.
5	16	1.3	15	1.5	1.5	0.6	0.6	M 4	E 1254/ 4
6	20	1.5	18	2.3	2.4	0.8	1.2	M 5	E 1254/ 5
7	20	2	20	2.5	2.7	0.9	1.3	M 6	E 1254/ 6
9	35	2.5	22	3	3.5	1.4	1.5	M 8	E 1254/ 8
9	35	3	22	3	4	1.4	1.5	M10	E 1254/10
10	55	4	28	4	6	2	2.7	M12	E 1254/12
45	100	5	32	5	7.5	2.5	3.2	M16	E 1254/16