


 
EYE BOLT
E 1270
PRODUCT DESCRIPTION

» According to DIN 580

MATERIAL

» C15E

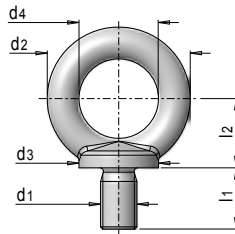

l1	l2	d2	d3	d4	d1	WLL	 max. kg	No.	EUR
						max. kg			
13	18	36	20	20	M8	140	100	E 1270/ 8	<>
17	22.5	45	25	25	M10	230	170	E 1270/10	<>
20	26	54	30	30	M12	340	240	E 1270/12	<>
27	30.5	63	35	35	M16	700	500	E 1270/16	<>
30	35	72	40	40	M20	1,200	860	E 1270/20	<>
36	45	90	50	50	M24	1,800	1,290	E 1270/24	<>
45	55	108	65	60	M30	3,200	2,300	E 1270/30	<>
54	65	126	75	70	M36	4,600	3,300	E 1270/36	<>
63	136.5	144	85	80	M42	6,300	4,500	E 1270/42	<>
68	152	166	100	90	M48	8,600	6,100	E 1270/48	<>