





### PRODUKTBESCHREIBUNG

- » Allseitig belastbar
- » 4-fache Sicherheit
- » Werkzeuglose Montage durch unverlierbares Schlüsselblech
- » Alle tragenden Bauteile 100% rissgeprüft bzw. nach EN 1677 prüfbelastet

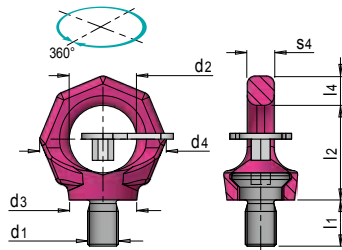

l1	l2	l4	d2	d3	d4	s4	d1	WLL				Nr.	EUR
								max. kg	max. kg	max. kg	max. kg		
9	28	9	20	23	37	7	<b>M 6</b>	500	100	200	140	E 1272/ 6	<>
12	35	11	25	25	47	9	<b>M 8</b>	1.000	300	600	420	E 1272/ 8	<>
15	35	11	25	25	47	9	<b>M10</b>	1.000	400	800	560	E 1272/10	<>
18	42	13	30	30	56	10	<b>M12</b>	2.000	750	1.500	1.000	E 1272/12	<>
24	49	15	35	36	65	13	<b>M16</b>	4.000	1.500	3.000	2.120	E 1272/16	<>
30	58	17	40	41	76	16	<b>M20</b>	6.000	2.300	4.600	3.220	E 1272/20	<>
36	70	20	49	51	92	19	<b>M24</b>	8.000	3.200	6.400	4.500	E 1272/24	<>
45	87	26	60	66	114	24	<b>M30</b>	12.000	4.500	9.000	6.300	E 1272/30	<>
54	103	32	72	76	135	29	<b>M36</b>	16.000	7.000	14.000	9.800	E 1272/36	<>
63	121	37	84	86	158	33	<b>M42</b>	24.000	9.000	18.000	12.600	E 1272/42	<>
72	138	42	94	100	180	42	<b>M48</b>	32.000	12.000	24.000	16.800	E 1272/48	<>

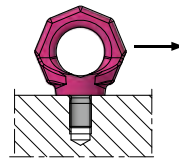

Nicht unter Last drehen!

Vor der Belastung in Kraftrichtung drehen!

Handfest anziehen, keine Verlängerung verwenden!