





PRODUKTBESCHREIBUNG

- » Einfache und werkzeuglose Montage und Demontage durch patentierten Federmechanismus
- » Allseitig belastbar
- » 360° drehbar - Positionierung in Belastungsrichtung
- » 100 % rissgeprüfte Schraube

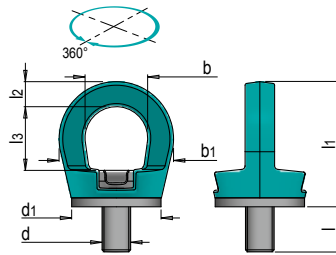

l	l1	l2	l3	b	b1	d1	d	WLL				Nr.	EUR
								max. kg	max. kg	max. kg	max. kg		
15	53	10	27	25	45	35	M 8	1.000	300	600	420	E 1272 M/ 8	<>
15	53	10	27	25	45	35	M10	1.500	500	1.000	700	E 1272 M/10	<>
20	63	12	32	30	55	43	M12	2.000	700	1.400	980	E 1272 M/12	<>
25	70	14	36	35	64	50	M16	4.000	1.500	3.000	2.100	E 1272 M/16	<>
30	81	16	41	40	73	54	M20	5.000	2.300	4.600	3.200	E 1272 M/20	<>
35	93	18	50	50	86	69	M24	6.500	3.200	6.400	4.500	E 1272 M/24	<>
45	114	25	60	60	110	90	M30	12.000	4.000	8.000	5.600	E 1272 M/30	<>
55	136	31	70	70	132	108	M36	15.000	7.000	14.000	9.800	E 1272 M/36	<>
65	153	36	72	80	152	126	M42	22.000	9.000	18.000	12.600	E 1272 M/42	<>
75	179	42	88	95	179	148	M48	30.000	12.000	24.000	16.900	E 1272 M/48	<>

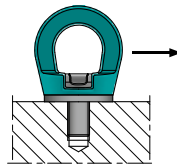

Nicht unter Last drehen!

Vor der Belastung in Kraftrichtung drehen!

Handfest anziehen, keine Verlängerung verwenden!