




PRODUCT DESCRIPTION

- » Equipped with a ball bearing system and thus 360° revolvable under load
- » Loadable in any direction
- » 100% crack tested screw

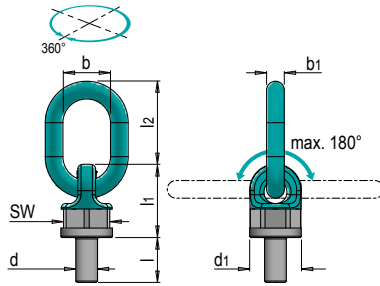

SW	l	l1	l2	b	b1	d1	d	WLL				No.	EUR
								max. kg	max. kg	max. kg	max. kg		
34	20	54	38	30	13	38	M10	1,200	500	1,000	700	E 1274 M/10	<>
34	22	54	48	35	13	38	M12	1,800	700	1,400	950	E 1274 M/12	<>
34	33	54	48	35	13	38	M16	2,800	1,500	3,000	2,100	E 1274 M/16	<>
46	33	75	55	35	16	55	M20	5,000	2,500	5,000	3,500	E 1274 M/20	<>
50	40	82	66	40	17	63	M24	7,000	4,000	8,000	5,500	E 1274 M/24	<>
60	40	92	70	50	23	72	M30	10,000	6,700	13,400	9,400	E 1274 M/30	<>
75	55	120	91	50	23	92	M36	12,500	8,000	16,000	11,200	E 1274 M/36	<>
75	60	120	91	65	27	92	M42	16,000	10,000	20,000	14,000	E 1274 M/42	<>
75	68	120	116	65	27	92	M48	16,000	12,500	25,000	17,500	E 1274 M/48	<>