
 
 


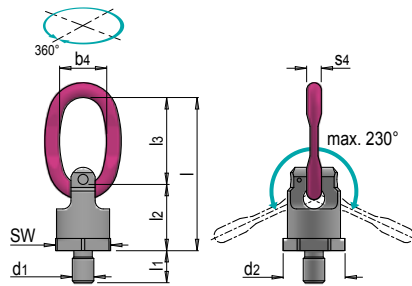



PRODUKTBESCHREIBUNG

- » Allseitig belastbar
- » 4-fache Sicherheit
- » Doppelt kugelgelagert für ruckfreies Kippen, Drehen und Wenden
- » Auch 90° zur Einschraubrichtung unter Volllast drehbar
- » Alle tragenden Bauteile 100% rissgeprüft bzw. nach EN 1677 prüfbelastet



SW	b4	l	l1	l2	l3	d2	s4	d1	 max. kg	 max. kg	 max. kg	 max. kg	Nr.	EUR
36	35	106	18	41	65	40	9	M12	630	630	1.260	880	E 1278/12	<>
41	35	115	24	50	65	46	11	M16	1.500	1.500	3.000	2.100	E 1278/16	<>
55	40	135	30	61	74	61	13	M20	2.500	2.500	5.000	3.500	E 1278/20	<>
70	45	172	36	77	95	78	16	M24	4.000	4.000	8.000	5.600	E 1278/24	<>
85	60	223	45	93	130	95	19	M30	6.700	5.000	10.000	7.000	E 1278/30	<>
90	65	242	54	102	140	100	24	M36	10.000	8.000	16.000	11.200	E 1278/36	<>