




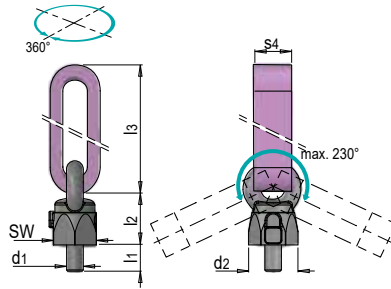



PRODUKTBESCHREIBUNG

- » Allseitig belastbar
- » 4-fache Sicherheit
- » Textil-Rundschlinge schützt empfindliche Oberflächen
- » Kugelgelagert und damit senkrecht unter Last drehbar
- » Alle tragenden Bauteile 100% rissgeprüft bzw. nach EN 1677 prüfbelastet



SW	s4	l1	l2	d2	d1	l3					Nr.	EUR
							max. kg	max. kg	max. kg	max. kg		
41	35	25	62	46	M16	500	1.300	1.300	2.600	1.820	E 1279/16/ 500	<>
41	35	25	62	46	M16	1000	1.300	1.300	2.600	1.820	E 1279/16/1000	<>
55	35	34	84	62	M20	500	2.000	2.000	4.000	2.800	E 1279/20/ 500	<>
55	35	34	84	62	M20	1000	2.000	2.000	4.000	2.800	E 1279/20/1000	<>
70	35	36	97	78	M24	500	2.000	3.000	6.000	4.250	E 1279/24/ 500	<>
70	35	36	97	78	M24	1000	2.000	3.000	6.000	4.250	E 1279/24/1000	<>