


PRODUCT DESCRIPTION

» Compatible to E 1288

MATERIAL

» 1.1191

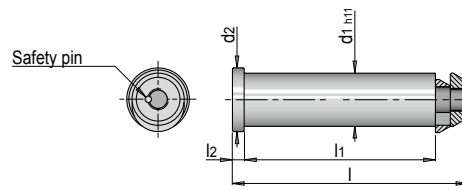

GSB[®]

CE



max. kg	l	l1	d2	l2	d1	No.	EUR
3,200	158	129	40	10	30	E 1289/30	<>
5,000	187	155	50	10	40	E 1289/40	<>
8,000	220	180	60	11	50	E 1289/50	<>
12,500	246	205	70	11	60	E 1289/60	<>

i For safety reasons, always take into account that two lifting pins must carry the weight of the entire die.

