


E 1302



Zylinderstift m6 für Sackloch

Dowel pin m6 for blind hole

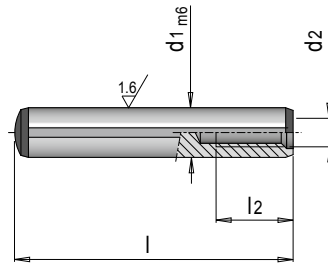

ISO 8735 (DIN 7979) ≈ 60 HRC

d2	l2	d1	l	Nr. / No.
M 3	6	5	10	E 1302/ 5 x 10
			12	E 1302/ 5 x 12
			16	E 1302/ 5 x 16
			20	E 1302/ 5 x 20
			24	E 1302/ 5 x 24
			28	E 1302/ 5 x 28
			32	E 1302/ 5 x 32
			40	E 1302/ 5 x 40
			50	E 1302/ 5 x 50
			M 4	6
16	E 1302/ 6 x 16			
20	E 1302/ 6 x 20			
24	E 1302/ 6 x 24			
28	E 1302/ 6 x 28			
32	E 1302/ 6 x 32			
40	E 1302/ 6 x 40			
50	E 1302/ 6 x 50			
60	E 1302/ 6 x 60			
80	E 1302/ 6 x 80			
M 5	8	8	16	E 1302/ 8 x 16
			20	E 1302/ 8 x 20
			24	E 1302/ 8 x 24
			28	E 1302/ 8 x 28
			32	E 1302/ 8 x 32
			36	E 1302/ 8 x 36
			40	E 1302/ 8 x 40
			50	E 1302/ 8 x 50
			60	E 1302/ 8 x 60
			70	E 1302/ 8 x 70
M 6	10	10	20	E 1302/10 x 20
			24	E 1302/10 x 24
			28	E 1302/10 x 28
			32	E 1302/10 x 32
			40	E 1302/10 x 40
			45	E 1302/10 x 45
			50	E 1302/10 x 50
			60	E 1302/10 x 60
			70	E 1302/10 x 70
			80	E 1302/10 x 80
		100	E 1302/10 x 100	
		12	24	E 1302/12 x 24
			28	E 1302/12 x 28
			32	E 1302/12 x 32
			40	E 1302/12 x 40
			50	E 1302/12 x 50
			60	E 1302/12 x 60
			70	E 1302/12 x 70
			80	E 1302/12 x 80
			90	E 1302/12 x 90
100	E 1302/12 x 100			
M 8	12	14	40	E 1302/14 x 40
			50	E 1302/14 x 50
			60	E 1302/14 x 60
			70	E 1302/14 x 70
			80	E 1302/14 x 80
		16	100	E 1302/14 x 100
			32	E 1302/16 x 32
			40	E 1302/16 x 40
			45	E 1302/16 x 45

d2	l2	d1	l	Nr. / No.
M 8	12	16	50	E 1302/16 x 50
			60	E 1302/16 x 60
			70	E 1302/16 x 70
			80	E 1302/16 x 80
			100	E 1302/16 x 100
			120	E 1302/16 x 120
M10	16	20	40	E 1302/20 x 40
			50	E 1302/20 x 50
			60	E 1302/20 x 60
			70	E 1302/20 x 70
			80	E 1302/20 x 80
			100	E 1302/20 x 100
			120	E 1302/20 x 120