


E 1317



Gleitplatte für Flachführung, vertikal

Gliding plate for flat guiding unit, vertical

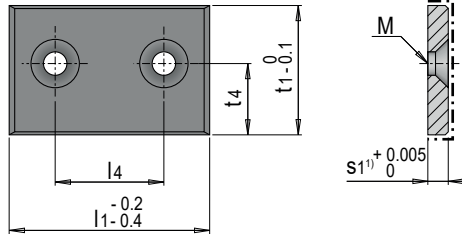

Mat.: 1.2842 ≈ 56 HRC

DLC beschichtet
coated

l1	l4	M	t4	t1	s1 ¹⁾	Nr. / No.
44	24	M 5	17	30	6	E 1317/30/ 6
62	36	M 6	22	38	6.2	E 1317/30/ 6,2
80	48		27	50	6	E 1317/38/ 6
98	60	M 8	38	70	6.2	E 1317/38/ 6,2
					8	E 1317/50/ 8
					8.3	E 1317/50/ 8,3
					10	E 1317/70/10
					10.3	E 1317/70/10,3

1) s1: 6.2, 8.3, 10.3 --> auf Passtoleranz einschleifen / s1: 6.2, 8.3, 10.3 --> to be adjusted to fitting tolerance

