

E 1323




Flachführungsleiste

Flat guiding stock

» Als Endzentrierung einsetzbar

» Can be used as a lock (for final centring)

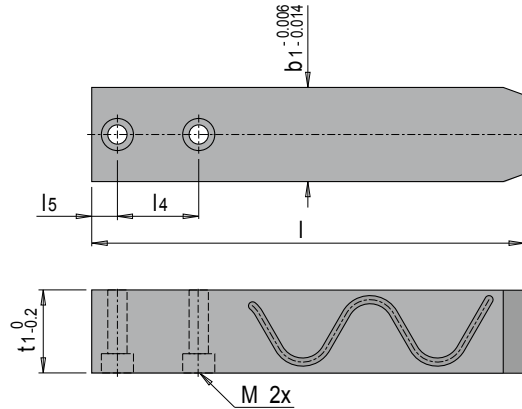

Mat.: 1.7131 ≈ 60 HRC

l4	l5	t1	M	b1	l	Nr. / No.
14	6	14	M 4	16	70	E 1323/16 x 70
					80	E 1323/16 x 80
					90	E 1323/16 x 90
18	8	22	M 5	25	88	E 1323/25 x 88
					108	E 1323/25 x 108
					128	E 1323/25 x 128
					98	E 1323/32 x 98
					138	E 1323/32 x 138
28	30	M 6	32	178	E 1323/32 x 178	
				218	E 1323/32 x 218	
				98	E 1323/34 x 98	
				138	E 1323/34 x 138	
				178	E 1323/34 x 178	
				218	E 1323/34 x 218	
				138	E 1323/44 x 138	
38	12	38	M 8	44	136	E 1323/44 x 136
					176	E 1323/44 x 176
					216	E 1323/44 x 216
					256	E 1323/44 x 256
					136	E 1323/46 x 136
					176	E 1323/46 x 176
					216	E 1323/46 x 216
48	16	50	M10	58	256	E 1323/46 x 256
					174	E 1323/58 x 174
					214	E 1323/58 x 214
					254	E 1323/58 x 254
					294	E 1323/58 x 294
				60	334	E 1323/58 x 334
					174	E 1323/60 x 174
					214	E 1323/60 x 214
					254	E 1323/60 x 254
					294	E 1323/60 x 294
58	20	70	M12	78	334	E 1323/60 x 334
					212	E 1323/78 x 212
					252	E 1323/78 x 252
					292	E 1323/78 x 292
					332	E 1323/78 x 332
				80	372	E 1323/78 x 372
					412	E 1323/78 x 412
					212	E 1323/80 x 212
					252	E 1323/80 x 252
					292	E 1323/80 x 292
332	E 1323/80 x 332					
372	E 1323/80 x 372					
412	E 1323/80 x 412					