


E 1375



Zentrierflansch mit Ansatz

Locating ring with neck

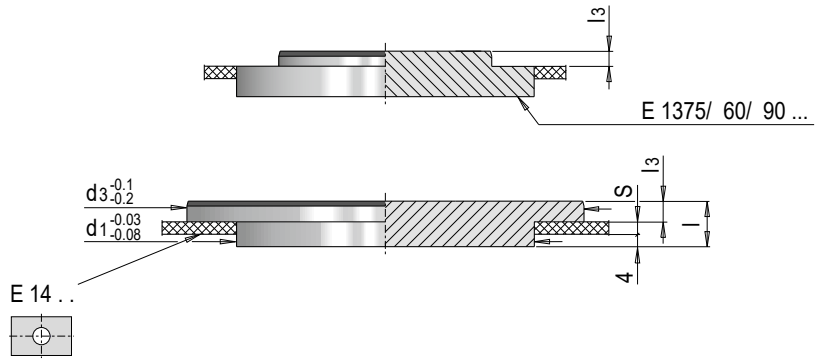

Mat.: 1.1730

min. 630N/mm²

l3	S	d3	d1	l	Nr. / No.
8	6	90	60	18	E 1375/ 90/ 60 x 18
4	-	60	90	8	E 1375/ 60/ 90 x 8
	6			14	E 1375/ 60/ 90 x 14
8	-	100		12	E 1375/100/ 90 x 12
	6			18	E 1375/100/ 90 x 18
	-	110		12	E 1375/110/ 90 x 12
	6			18	E 1375/110/ 90 x 18
	8			20	E 1375/110/ 90 x 20
	-	120		12	E 1375/120/ 90 x 12
	6			18	E 1375/120/ 90 x 18
	8			20	E 1375/120/ 90 x 20
	-	125		12	E 1375/125/ 90 x 12
	6			18	E 1375/125/ 90 x 18
	8			20	E 1375/125/ 90 x 20
18				30	E 1375/125/ 90 x 30
8	-	160		12	E 1375/160/ 90 x 12
	6			18	E 1375/160/ 90 x 18
	8			20	E 1375/160/ 90 x 20
18				30	E 1375/160/ 90 x 30
8	-	175		12	E 1375/175/ 90 x 12
	6			18	E 1375/175/ 90 x 18
	8			20	E 1375/175/ 90 x 20
			160		E 1375/175/160 x 20
10	6			22	E 1375/175/160 x 22
	8			14	E 1375/200/160 x 14
	-	200		22	E 1375/200/160 x 22
	8			30	E 1375/200/160 x 30
18				14	E 1375/250/160 x 14
10	-	250		22	E 1375/250/160 x 22
	8			30	E 1375/250/160 x 30