


E 1380



Zentrierflansch ohne Ansatz

Locating ring without neck

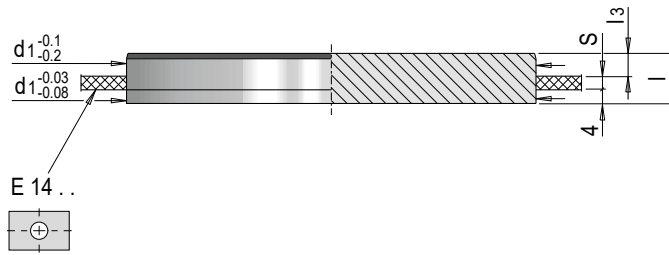

Mat.: 1.1730 min. 630 N/mm²

l3	S	d1	l	Nr. / No.
4	-	60	8	E 1380/ 60 x 8
	6		14	E 1380/ 60 x 14
8	-	90	12	E 1380/ 90 x 12
	6		18	E 1380/ 90 x 18
14	8		26	E 1380/ 90 x 26
8	-	100	12	E 1380/100 x 12
	6		18	E 1380/100 x 18
14	8		26	E 1380/100 x 26
8	-	110	12	E 1380/110 x 12
	6		18	E 1380/110 x 18
14	8		26	E 1380/110 x 26
8	-	125	12	E 1380/125 x 12
	6		18	E 1380/125 x 18
	8		20	E 1380/125 x 20
18			30	E 1380/125 x 30
10	-	160	14	E 1380/160 x 14
	6		20	E 1380/160 x 20
	8		22	E 1380/160 x 22
18			30	E 1380/160 x 30
10	-	175	14	E 1380/175 x 14
	8		22	E 1380/175 x 22
18			30	E 1380/175 x 30
10	-	200	14	E 1380/200 x 14
	8		22	E 1380/200 x 22
18			30	E 1380/200 x 30
10	-	250	14	E 1380/250 x 14
	8		22	E 1380/250 x 22
18			30	E 1380/250 x 30