


E 15581



Elastomer - Hohlrundstab, 90 Shore A

Elastomer hollow round section, 90 Shore A

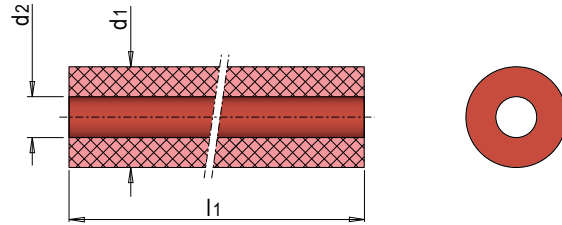

Mat.: PUR (90 Shore A)

t max = 80°C

d2	d1	l1	Nr. / No.
6.5	16	200	E 15581/ 16 x 200
8.5	20	290	E 15581/ 20 x 290
10.5	25		E 15581/ 25 x 290
13.5	32	500	E 15581/ 32 x 500
	40		E 15581/ 40 x 500
17	50		E 15581/ 50 x 500