


E 15582



Elastomer - Rundstab, 90 Shore A

Elastomer round section, 90 Shore A

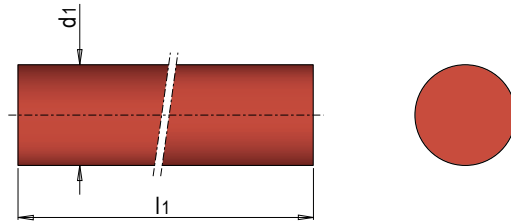

Mat.: PUR (90 Shore A)

t max = 80°C

d1	l1	Nr. / No.
8	200	E 15582/ 8 x 200
10		E 15582/10 x 200
12		E 15582/12 x 200
16	300	E 15582/16 x 300
20		E 15582/20 x 300
25		E 15582/25 x 300
32		E 15582/32 x 300
40	400	E 15582/40 x 300
50		E 15582/50 x 400
63		E 15582/63 x 400
80		E 15582/80 x 400