


E 1561



Führungseinheit mit Anschlag

Guiding unit with stopper

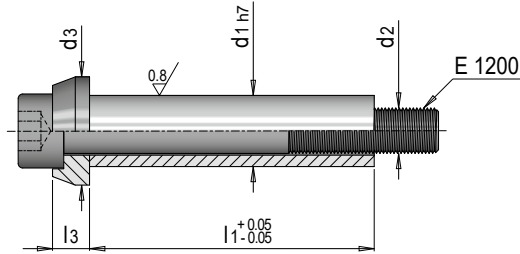

Mat.: Stahl / steel 12.9

d3	l3	d2	E 1200/.. x ..	d1	l1	Nr. / No.				
15	6	M 6	E 1200/ 6 x 30	10	15	E 1561/10 x 15				
			E 1200/ 6 x 35		20	E 1561/10 x 20				
			E 1200/ 6 x 40		25	E 1561/10 x 25				
			E 1200/ 6 x 45		30	E 1561/10 x 30				
			E 1200/ 6 x 50		35	E 1561/10 x 35				
			E 1200/ 6 x 55		40	E 1561/10 x 40				
			E 1200/ 6 x 60		45	E 1561/10 x 45				
			E 1200/ 6 x 65		50	E 1561/10 x 50				
			E 1200/ 6 x 70		55	E 1561/10 x 55				
			E 1200/ 6 x 80		60	E 1561/10 x 60				
					65	E 1561/10 x 65				
					70	E 1561/10 x 70				
					80	E 1561/10 x 80				
					90	E 1561/10 x 90				
					100	E 1561/10 x 100				
					110	E 1561/10 x 110				
			19		6.5	M 8	E 1200/ 8 x 35	12.5	20	E 1561/12,5 x 20
							E 1200/ 8 x 40		25	E 1561/12,5 x 25
							E 1200/ 8 x 45		30	E 1561/12,5 x 30
E 1200/ 8 x 50	35	E 1561/12,5 x 35								
E 1200/ 8 x 55	40	E 1561/12,5 x 40								
E 1200/ 8 x 60	45	E 1561/12,5 x 45								
E 1200/ 8 x 65	50	E 1561/12,5 x 50								
E 1200/ 8 x 70	55	E 1561/12,5 x 55								
E 1200/ 8 x 80	60	E 1561/12,5 x 60								
	65	E 1561/12,5 x 65								
	70	E 1561/12,5 x 70								
	80	E 1561/12,5 x 80								
	90	E 1561/12,5 x 90								
	100	E 1561/12,5 x 100								
	110	E 1561/12,5 x 110								
	120	E 1561/12,5 x 120								
	140	E 1561/12,5 x 140								
23	7.5	M10		E 1200/10 x 40			15		20	E 1561/15 x 20
				E 1200/10 x 45					25	E 1561/15 x 25
			E 1200/10 x 50	30	E 1561/15 x 30					
			E 1200/10 x 55	35	E 1561/15 x 35					
			E 1200/10 x 60	40	E 1561/15 x 40					
			E 1200/10 x 65	45	E 1561/15 x 45					
			E 1200/10 x 70	50	E 1561/15 x 50					
			E 1200/10 x 75	55	E 1561/15 x 55					
			E 1200/10 x 80	60	E 1561/15 x 60					
			E 1200/10 x 85	65	E 1561/15 x 65					
			E 1200/10 x 90	70	E 1561/15 x 70					
			E 1200/10 x 100	80	E 1561/15 x 80					
			E 1200/10 x 110	90	E 1561/15 x 90					
			E 1200/10 x 120	100	E 1561/15 x 100					
			E 1200/10 x 130	110	E 1561/15 x 110					
			E 1200/10 x 140	120	E 1561/15 x 120					
			E 1200/10 x 160	140	E 1561/15 x 140					
			E 1200/10 x 170	150	E 1561/15 x 150					
			E 1200/10 x 180	160	E 1561/15 x 160					
E 1200/10 x 200	180	E 1561/15 x 180								
E 1200/10 x 220	200	E 1561/15 x 200								
27	9	M12	E 1200/12 x 50	17.5	30	E 1561/17,5 x 30				
			E 1200/12 x 60		35	E 1561/17,5 x 35				
					40	E 1561/17,5 x 40				
					45	E 1561/17,5 x 45				
					50	E 1561/17,5 x 50				
					55	E 1561/17,5 x 55				
					60	E 1561/17,5 x 60				

d3	l3	d2	E 1200/.. x ..	d1	l1	Nr. / No.
27	9	M12	E 1200/12 x 90	17.5	65	E 1561/17,5 x 65
			E 1200/12 x 100		70	E 1561/17,5 x 70
			E 1200/12 x 110		80	E 1561/17,5 x 80
			E 1200/12 x 120		90	E 1561/17,5 x 90
			E 1200/12 x 130		100	E 1561/17,5 x 100
			E 1200/12 x 140		110	E 1561/17,5 x 110
			E 1200/12 x 150		120	E 1561/17,5 x 120
			E 1200/12 x 180		140	E 1561/17,5 x 140
					150	E 1561/17,5 x 150
					160	E 1561/17,5 x 160
					180	E 1561/17,5 x 180
					200	E 1561/17,5 x 200
	220	E 1561/17,5 x 220				
34	11	M16	E 1200/16 x 70	23	40	E 1561/23 x 40
			E 1200/16 x 75		45	E 1561/23 x 45
			E 1200/16 x 80		50	E 1561/23 x 50
			E 1200/16 x 90		55	E 1561/23 x 55
					60	E 1561/23 x 60
					65	E 1561/23 x 65
					70	E 1561/23 x 70
					80	E 1561/23 x 80
					90	E 1561/23 x 90
					100	E 1561/23 x 100
					110	E 1561/23 x 110
					120	E 1561/23 x 120
	140	E 1561/23 x 140				
	150	E 1561/23 x 150				
	160	E 1561/23 x 160				
	180	E 1561/23 x 180				
	200	E 1561/23 x 200				
	220	E 1561/23 x 220				
	230	E 1561/23 x 230				

