


E 1567



Distanzrohr

Distance sleeve

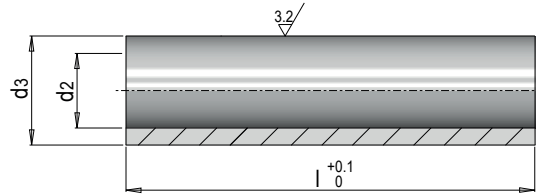

Mat.: 1.0308 ≈ 54 HRC

d2	d3	l	Nr. / No.
6.6	10	20	E 1567/10 x 20
		25	E 1567/10 x 25
		30	E 1567/10 x 30
		32	E 1567/10 x 32
		40	E 1567/10 x 40
		50	E 1567/10 x 50
		63	E 1567/10 x 63
		80	E 1567/10 x 80
8.6	12.5	20	E 1567/12,5 x 20
		30	E 1567/12,5 x 30
		32	E 1567/12,5 x 32
		40	E 1567/12,5 x 40
		50	E 1567/12,5 x 50
		63	E 1567/12,5 x 63
		80	E 1567/12,5 x 80
		100	E 1567/12,5 x 100
11	16	30	E 1567/16 x 30
		32	E 1567/16 x 32
		40	E 1567/16 x 40
		50	E 1567/16 x 50
		63	E 1567/16 x 63
		80	E 1567/16 x 80
		100	E 1567/16 x 100
		125	E 1567/16 x 125
13	20	150	E 1567/16 x 150
		30	E 1567/20 x 30
		40	E 1567/20 x 40
		50	E 1567/20 x 50
		63	E 1567/20 x 63
		80	E 1567/20 x 80
		100	E 1567/20 x 100
		125	E 1567/20 x 125
17	25	150	E 1567/20 x 150
		40	E 1567/25 x 40
		50	E 1567/25 x 50
		63	E 1567/25 x 63
		80	E 1567/25 x 80
		100	E 1567/25 x 100
26	36	125	E 1567/25 x 125
		150	E 1567/25 x 150
		80	E 1567/36 x 80
		100	E 1567/36 x 100
		125	E 1567/36 x 125
		150	E 1567/36 x 150
		200	E 1567/36 x 200