


E 1575

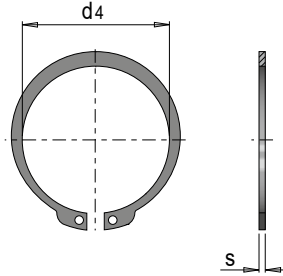

Sicherungsring für Wellen

External circlip for shafts



Ausführung Federstahl, phosphatiert oder brüniert
Spring steel version, Phosphated or black oxidized

DIN 471

l1	l2 min.	d2	d3	d4	s	d1	Nr. / No.
1.1	0.6	8.6	16	8.4	1	9	E 1575/ 9
		9.6	17.6	9.3		10	E 1575/10
	11.5	19.6	11	12		E 1575/12	
	13.4	22	12.9	14		E 1575/14	
	14.3	22.6	13.8	15		E 1575/15	
1.3	1.5	15.2	23.8	14.7	1.2	16	E 1575/16
		17	26.8	16.5		18	E 1575/18
		19	29	18.5		20	E 1575/20
	1.7	21	30.8	20.5		22	E 1575/22
		22.9	33.2	22.2		24	E 1575/24
1.6	2.1	23.9	34.2	23.2	1.5	25	E 1575/25
		24.9	35.5	24.2		26	E 1575/26
		27.6	39.1	26.9		29	E 1575/29
	28.6	40.5	27.9	30		E 1575/30	
1.85	2.6	30.3	43	29.6	1.75	32	E 1575/32
		33	46.8	32.2		35	E 1575/35
	3.8	35	49.4	34.2		37	E 1575/37
		36	50.2	35.2		38	E 1575/38
		37.5	52.6	36.5		40	E 1575/40
		39.5	55.7	38.5		42	E 1575/42
2.15	4.5	42.5	59.1	41.5	2	45	E 1575/45
		44.5	61.6	43.5		47	E 1575/47
		45.5	63	44.5		48	E 1575/48
		47	64.5	45.8		50	E 1575/50
		49	66	47.8		52	E 1575/52
2.65	5.3	51	69.2	49.8	2.5	54	E 1575/54
		54	72.6	52.8		57	E 1575/57
		62	81.4	60.8		65	E 1575/65
3.15	5.3	67	87	65.5	3	70	E 1575/70
		76.5	98	74.5		80	E 1575/80
		88.5	111.3	86.5		92	E 1575/92

