


E 1710 DLC



Auswerferstift gehärtet mit DLC - Beschichtung

Ejector pin, through-hardened, with DLC coating

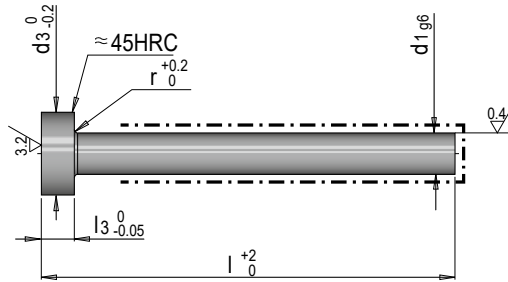

Mat.: ~1.2210 ≈ 60HRC

≈ ISO 6751 (DIN 1530 A)
Form AH

--- DLC --- beschichtet
coated

r	l3	d3	d1	l	Nr. / No.
0.2	1.2	2.5	0.5	100	E 1710 DLC/ 0,5 x 100
0.2	1.2	2.5	0.6	100	E 1710 DLC/ 0,6 x 100
0.2	1.2	2.5	0.7	100	E 1710 DLC/ 0,7 x 100
0.2	1.2	2.5	0.8	80	E 1710 DLC/ 0,8 x 80
				100	E 1710 DLC/ 0,8 x 100
				125	E 1710 DLC/ 0,8 x 125
				160	E 1710 DLC/ 0,8 x 160
				200	E 1710 DLC/ 0,9 x 100
0.2	1.2	2.5	0.9	100	E 1710 DLC/ 0,9 x 100
0.2	1.2	2.5	1	80	E 1710 DLC/ 1 x 80
				100	E 1710 DLC/ 1 x 100
				125	E 1710 DLC/ 1 x 125
				160	E 1710 DLC/ 1 x 160
0.2	1.2	2.5	1.1	80	E 1710 DLC/ 1,1 x 80
				100	E 1710 DLC/ 1,1 x 100
				125	E 1710 DLC/ 1,1 x 125
				160	E 1710 DLC/ 1,1 x 160
				200	E 1710 DLC/ 1,1 x 200
0.2	1.2	2.5	1.2	80	E 1710 DLC/ 1,2 x 80
				100	E 1710 DLC/ 1,2 x 100
				125	E 1710 DLC/ 1,2 x 125
				160	E 1710 DLC/ 1,2 x 160
				200	E 1710 DLC/ 1,2 x 200
0.2	1.5	3	1.3	80	E 1710 DLC/ 1,3 x 80
				100	E 1710 DLC/ 1,3 x 100
				125	E 1710 DLC/ 1,3 x 125
				160	E 1710 DLC/ 1,3 x 160
				200	E 1710 DLC/ 1,3 x 200
0.2	1.5	3	1.4	80	E 1710 DLC/ 1,4 x 80
				100	E 1710 DLC/ 1,4 x 100
				125	E 1710 DLC/ 1,4 x 125
				160	E 1710 DLC/ 1,4 x 160
				200	E 1710 DLC/ 1,4 x 200
0.2	1.5	3	1.5	80	E 1710 DLC/ 1,5 x 80
				100	E 1710 DLC/ 1,5 x 100
				125	E 1710 DLC/ 1,5 x 125
				160	E 1710 DLC/ 1,5 x 160
				200	E 1710 DLC/ 1,5 x 200
0.2	1.5	3	1.6	80	E 1710 DLC/ 1,6 x 80
				100	E 1710 DLC/ 1,6 x 100
				125	E 1710 DLC/ 1,6 x 125
				160	E 1710 DLC/ 1,6 x 160
				200	E 1710 DLC/ 1,6 x 200
0.2	1.5	3	1.7	80	E 1710 DLC/ 1,7 x 80
				100	E 1710 DLC/ 1,7 x 100
				125	E 1710 DLC/ 1,7 x 125
				160	E 1710 DLC/ 1,7 x 160
				200	E 1710 DLC/ 1,7 x 200
0.2	1.5	3	1.8	80	E 1710 DLC/ 1,8 x 80
				100	E 1710 DLC/ 1,8 x 100
				125	E 1710 DLC/ 1,8 x 125
				160	E 1710 DLC/ 1,8 x 160
				200	E 1710 DLC/ 1,8 x 200
0.2	1.5	3	1.9	80	E 1710 DLC/ 1,9 x 80
				100	E 1710 DLC/ 1,9 x 100
				125	E 1710 DLC/ 1,9 x 125

r	l3	d3	d1	l	Nr. / No.
0.2	1.5	3	1.9	160	E 1710 DLC/ 1,9 x 160
				200	E 1710 DLC/ 1,9 x 200
0.2	2	4	2	80	E 1710 DLC/ 2 x 80
				100	E 1710 DLC/ 2 x 100
				125	E 1710 DLC/ 2 x 125
				160	E 1710 DLC/ 2 x 160
				200	E 1710 DLC/ 2 x 200
				250	E 1710 DLC/ 2 x 250
				315	E 1710 DLC/ 2 x 315
0.2	2	4	2.1	400	E 1710 DLC/ 2 x 400
				125	E 1710 DLC/ 2,1 x 125
				200	E 1710 DLC/ 2,1 x 200
0.2	2	4	2.2	315	E 1710 DLC/ 2,1 x 315
				100	E 1710 DLC/ 2,2 x 100
				125	E 1710 DLC/ 2,2 x 125
0.2	2	4	2.3	160	E 1710 DLC/ 2,2 x 160
				200	E 1710 DLC/ 2,2 x 200
				250	E 1710 DLC/ 2,2 x 250
				315	E 1710 DLC/ 2,2 x 315
				125	E 1710 DLC/ 2,3 x 125
0.2	2	4	2.4	200	E 1710 DLC/ 2,3 x 200
				125	E 1710 DLC/ 2,4 x 125
				200	E 1710 DLC/ 2,4 x 200
0.3	2	5	2.5	80	E 1710 DLC/ 2,5 x 80
				100	E 1710 DLC/ 2,5 x 100
				125	E 1710 DLC/ 2,5 x 125
				160	E 1710 DLC/ 2,5 x 160
				200	E 1710 DLC/ 2,5 x 200
				250	E 1710 DLC/ 2,5 x 250
				315	E 1710 DLC/ 2,5 x 315
0.3	2	5	2.6	400	E 1710 DLC/ 2,5 x 400
				125	E 1710 DLC/ 2,6 x 125
				200	E 1710 DLC/ 2,6 x 200
				250	E 1710 DLC/ 2,6 x 250
0.3	2	5	2.7	100	E 1710 DLC/ 2,7 x 100
				125	E 1710 DLC/ 2,7 x 125
				160	E 1710 DLC/ 2,7 x 160
				200	E 1710 DLC/ 2,7 x 200
0.3	2	5	2.8	250	E 1710 DLC/ 2,7 x 250
				160	E 1710 DLC/ 2,8 x 160
				250	E 1710 DLC/ 2,8 x 250
				80	E 1710 DLC/ 3 x 80
0.3	3	6	3	100	E 1710 DLC/ 3 x 100
				125	E 1710 DLC/ 3 x 125
				160	E 1710 DLC/ 3 x 160
				200	E 1710 DLC/ 3 x 200
				250	E 1710 DLC/ 3 x 250
0.3	3	6	3.1	315	E 1710 DLC/ 3 x 315
				400	E 1710 DLC/ 3 x 400
				500	E 1710 DLC/ 3 x 500
				125	E 1710 DLC/ 3,1 x 125
				200	E 1710 DLC/ 3,1 x 200
0.3	3	6	3.2	315	E 1710 DLC/ 3,1 x 315
				100	E 1710 DLC/ 3,2 x 100
				125	E 1710 DLC/ 3,2 x 125
0.3	3	6	3.3	160	E 1710 DLC/ 3,2 x 160
				200	E 1710 DLC/ 3,2 x 200
				250	E 1710 DLC/ 3,2 x 250
				315	E 1710 DLC/ 3,2 x 315
				400	E 1710 DLC/ 3,2 x 400
				160	E 1710 DLC/ 3,3 x 160
250	E 1710 DLC/ 3,3 x 250				



r	l3	d3	d1	l	Nr./No.				
0.3	3	6	3.4	160	E 1710 DLC/ 3,4 x 160				
				250	E 1710 DLC/ 3,4 x 250				
0.3	3	7	3.5	100	E 1710 DLC/ 3,5 x 100				
				125	E 1710 DLC/ 3,5 x 125				
				160	E 1710 DLC/ 3,5 x 160				
				200	E 1710 DLC/ 3,5 x 200				
				250	E 1710 DLC/ 3,5 x 250				
				315	E 1710 DLC/ 3,5 x 315				
				400	E 1710 DLC/ 3,5 x 400				
				500	E 1710 DLC/ 3,5 x 500				
0.3	3	7	3.6	160	E 1710 DLC/ 3,6 x 160				
				250	E 1710 DLC/ 3,6 x 250				
0.3	3	7	3.7	100	E 1710 DLC/ 3,7 x 100				
				160	E 1710 DLC/ 3,7 x 160				
				250	E 1710 DLC/ 3,7 x 250				
0.3	3	7	3.8	160	E 1710 DLC/ 3,8 x 160				
				250	E 1710 DLC/ 3,8 x 250				
0.3	3	8	4	80	E 1710 DLC/ 4 x 80				
				100	E 1710 DLC/ 4 x 100				
				125	E 1710 DLC/ 4 x 125				
				160	E 1710 DLC/ 4 x 160				
				200	E 1710 DLC/ 4 x 200				
				250	E 1710 DLC/ 4 x 250				
				315	E 1710 DLC/ 4 x 315				
				400	E 1710 DLC/ 4 x 400				
				500	E 1710 DLC/ 4 x 500				
				0.3	3	8	4.2	100	E 1710 DLC/ 4,2 x 100
125	E 1710 DLC/ 4,2 x 125								
160	E 1710 DLC/ 4,2 x 160								
200	E 1710 DLC/ 4,2 x 200								
250	E 1710 DLC/ 4,2 x 250								
0.3	3	8	4.5	100	E 1710 DLC/ 4,5 x 100				
				125	E 1710 DLC/ 4,5 x 125				
				160	E 1710 DLC/ 4,5 x 160				
				200	E 1710 DLC/ 4,5 x 200				
				250	E 1710 DLC/ 4,5 x 250				
0.3	3	8	4.7	100	E 1710 DLC/ 4,7 x 100				
				160	E 1710 DLC/ 4,7 x 160				
				250	E 1710 DLC/ 4,7 x 250				
				160	E 1710 DLC/ 4,8 x 160				
				250	E 1710 DLC/ 4,8 x 250				
0.3	3	10	5	80	E 1710 DLC/ 5 x 80				
				100	E 1710 DLC/ 5 x 100				
				125	E 1710 DLC/ 5 x 125				
				160	E 1710 DLC/ 5 x 160				
				200	E 1710 DLC/ 5 x 200				
				250	E 1710 DLC/ 5 x 250				
				315	E 1710 DLC/ 5 x 315				
				400	E 1710 DLC/ 5 x 400				
				500	E 1710 DLC/ 5 x 500				
				0.3	3	10	5.2	100	E 1710 DLC/ 5,2 x 100
125	E 1710 DLC/ 5,2 x 125								
160	E 1710 DLC/ 5,2 x 160								
200	E 1710 DLC/ 5,2 x 200								
250	E 1710 DLC/ 5,2 x 250								
0.3	3	10	5.5	100	E 1710 DLC/ 5,5 x 100				
				125	E 1710 DLC/ 5,5 x 125				
				160	E 1710 DLC/ 5,5 x 160				
				200	E 1710 DLC/ 5,5 x 200				
				250	E 1710 DLC/ 5,5 x 250				
0.3	3	10	5.6	160	E 1710 DLC/ 5,6 x 160				
				250	E 1710 DLC/ 5,6 x 250				
				160	E 1710 DLC/ 5,8 x 160				
0.3	3	10	5.8	250	E 1710 DLC/ 5,8 x 250				
				80	E 1710 DLC/ 6 x 80				
0.5	5	12	6	100	E 1710 DLC/ 6 x 100				
				125	E 1710 DLC/ 6 x 125				
				160	E 1710 DLC/ 6 x 160				
				200	E 1710 DLC/ 6 x 200				
				250	E 1710 DLC/ 6 x 250				
				315	E 1710 DLC/ 6 x 315				
				400	E 1710 DLC/ 6 x 400				
				500	E 1710 DLC/ 6 x 500				
				0.5	5	12	6.2	100	E 1710 DLC/ 6,2 x 100
								125	E 1710 DLC/ 6,2 x 125
160	E 1710 DLC/ 6,2 x 160								
200	E 1710 DLC/ 6,2 x 200								
250	E 1710 DLC/ 6,2 x 250								
0.5	5	12	6.5	100	E 1710 DLC/ 6,5 x 100				
				125	E 1710 DLC/ 6,5 x 125				
				160	E 1710 DLC/ 6,5 x 160				
				200	E 1710 DLC/ 6,5 x 200				
				250	E 1710 DLC/ 6,5 x 250				

r	l3	d3	d1	l	Nr./No.
0.5	5	12	6.5	250	E 1710 DLC/ 6,5 x 250
				315	E 1710 DLC/ 6,5 x 315
0.5	5	12	7	100	E 1710 DLC/ 7 x 100
				125	E 1710 DLC/ 7 x 125
				160	E 1710 DLC/ 7 x 160
				200	E 1710 DLC/ 7 x 200
				250	E 1710 DLC/ 7 x 250
				315	E 1710 DLC/ 7 x 315
				400	E 1710 DLC/ 7 x 400
				500	E 1710 DLC/ 7 x 500
0.5	5	12	7.5	100	E 1710 DLC/ 7,5 x 100
				160	E 1710 DLC/ 7,5 x 160
				250	E 1710 DLC/ 7,5 x 250
0.5	5	14	8	100	E 1710 DLC/ 8 x 100
				125	E 1710 DLC/ 8 x 125
				160	E 1710 DLC/ 8 x 160
				200	E 1710 DLC/ 8 x 200
				250	E 1710 DLC/ 8 x 250
0.5	5	14	8.2	315	E 1710 DLC/ 8 x 315
				400	E 1710 DLC/ 8 x 400
				500	E 1710 DLC/ 8 x 500
				630	E 1710 DLC/ 8 x 630
				100	E 1710 DLC/ 8,2 x 100
				125	E 1710 DLC/ 8,2 x 125
				160	E 1710 DLC/ 8,2 x 160
0.5	5	14	8.5	200	E 1710 DLC/ 8,2 x 200
				250	E 1710 DLC/ 8,2 x 250
				315	E 1710 DLC/ 8,2 x 315
				100	E 1710 DLC/ 8,5 x 100
				125	E 1710 DLC/ 8,5 x 125
0.5	5	14	9	160	E 1710 DLC/ 8,5 x 160
				200	E 1710 DLC/ 8,5 x 200
				250	E 1710 DLC/ 8,5 x 250
				315	E 1710 DLC/ 8,5 x 315
				100	E 1710 DLC/ 9 x 100
0.5	5	16	10	160	E 1710 DLC/ 9 x 160
				250	E 1710 DLC/ 9 x 250
				400	E 1710 DLC/ 9 x 400
				100	E 1710 DLC/ 10 x 100
0.5	5	16	10.5	125	E 1710 DLC/ 10 x 125
				160	E 1710 DLC/ 10 x 160
				200	E 1710 DLC/ 10 x 200
				250	E 1710 DLC/ 10 x 250
				315	E 1710 DLC/ 10 x 315
				400	E 1710 DLC/ 10 x 400
				500	E 1710 DLC/ 10 x 500
0.5	5	16	10.5	630	E 1710 DLC/ 10 x 630
				100	E 1710 DLC/ 10,5 x 100
				160	E 1710 DLC/ 10,5 x 160
				250	E 1710 DLC/ 10,5 x 250
				100	E 1710 DLC/ 12 x 100
0.8	7	18	12	125	E 1710 DLC/ 12 x 125
				160	E 1710 DLC/ 12 x 160
				200	E 1710 DLC/ 12 x 200
				250	E 1710 DLC/ 12 x 250
				315	E 1710 DLC/ 12 x 315
0.8	7	18	12.5	400	E 1710 DLC/ 12 x 400
				500	E 1710 DLC/ 12 x 500
				100	E 1710 DLC/ 12,5 x 100
				160	E 1710 DLC/ 12,5 x 160
				250	E 1710 DLC/ 12,5 x 250
0.8	7	18	13	100	E 1710 DLC/ 13 x 100
				160	E 1710 DLC/ 13 x 160
				250	E 1710 DLC/ 13 x 250
0.8	7	22	14	100	E 1710 DLC/ 14 x 100
				160	E 1710 DLC/ 14 x 160
				250	E 1710 DLC/ 14 x 250
				400	E 1710 DLC/ 14 x 400
0.8	7	22	16	100	E 1710 DLC/ 16 x 100
				125	E 1710 DLC/ 16 x 125
				160	E 1710 DLC/ 16 x 160
				200	E 1710 DLC/ 16 x 200
				250	E 1710 DLC/ 16 x 250
				315	E 1710 DLC/ 16 x 315
				400	E 1710 DLC/ 16 x 400
1	8	26	20	500	E 1710 DLC/ 16 x 500
				125	E 1710 DLC/ 20 x 125
				200	E 1710 DLC/ 20 x 200
				315	E 1710 DLC/ 20 x 315
				500	E 1710 DLC/ 20 x 500