


E 2040



Schlauchtülle

Hose nozzle

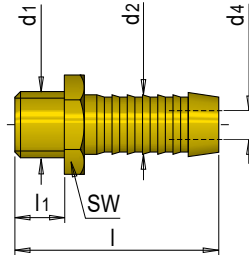

Mat.: 2.0401 (CuZn)

p max. = 15 bar

SW	l	l1	d4	d2	d1	Nr./No.
11	33	7	4.5	9	M 8 x 0,75	E 2040/ 9/ 8
			6		M10 x 1	E 2040/ 9/ 10
15	37.5	9	6	9	G 1/8"	E 2040/ 9/1/8
17					G 1/4"	E 2040/ 9/1/4
15	40	9	6	13	G 3/8"	E 2040/ 9/3/8
17					M12 x 1,5	E 2040/13/ 12
15	40	9	6	13	M14 x 1,5	E 2040/13/ 14
17					G 1/4"	E 2040/13/1/4
22	43	12	10	19	G 3/8"	E 2040/13/3/8
22	50	12	10		G 1/2"	E 2040/13/1/2
27	56	16	13	19	G 3/4"	E 2040/19/1/2
27	56	16	13	19	G 3/4"	E 2040/19/3/4