


E 20445



Schnellstecktülle mit Gewinde 90°

Quick-fit nozzle, threaded 90°

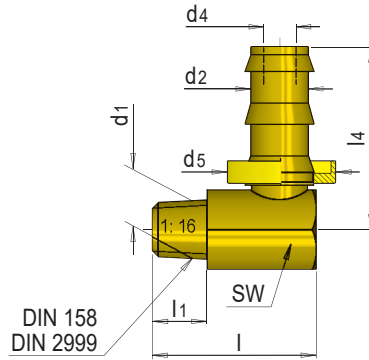

Mat.: 2.0401 (CuZn)

p max. = 15 bar t max = 140°C

SW	l	l1	l4	d4	d5	d2	d1	Nr. / No.
15	27	9	39	6	18	10	M10x1	E 20445/10/ 10
							R 1/8"	E 20445/10/1/8
17	34	11	40	9	22	13	M14x1,5	E 20445/13/ 14
							R 1/4"	E 20445/13/1/4

i Schnellstecktülle nur mit geeignetem Schnellsteckschlauch kombinieren (E 2185)
Use quick-fit nozzle only with suitable quick-fit hose (E 2185)