


E 20725

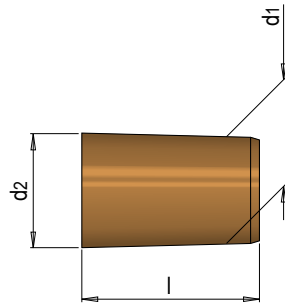

Verschlussstopfen Kupfer

Copper sealing plug



Mat.: Cu

p max = 20 bar

t max. = 160°C

l	d2	d1	Nr. / No.
8	4.4	4	E 20725/ 4
	5.4	5	E 20725/ 5
10	6.4	6	E 20725/ 6
12	8.4	8	E 20725/ 8
14	10.4	10	E 20725/10
15	12.4	12	E 20725/12

