


E 2185




Schnellsteck- Temperierschlauch

Quick-fit coolant hose

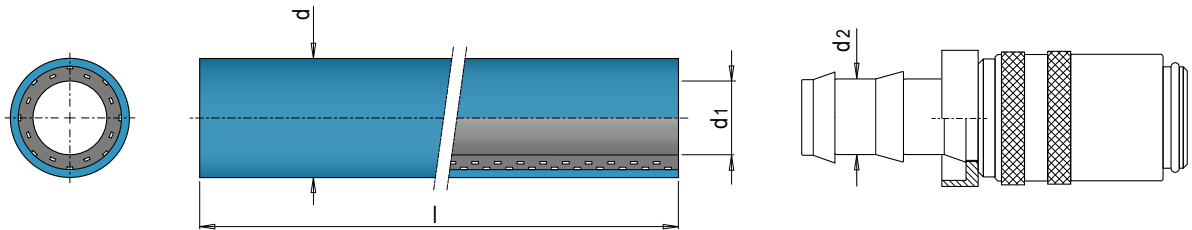

Mat.: Synthetischer Gummi
Synthetic rubber

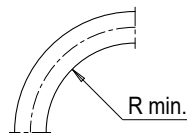

p max. = 28 bar t max. = 140°C

Farbe / Colour	R min.	Berstdruck / Bursting pressure	d	d1	d2	l	Nr. / No.	
● blau / blue	80	200	16	10	10	10 m	E 2185/10/10/B	
● rot / red							E 2185/10/10/R	
● schwarz / black							E 2185/10/10/S	
● blau / blue	90	200	20	12.7	13	40 m	E 2185/10/40/B	
● rot / red							E 2185/10/40/R	
● schwarz / black							E 2185/10/40/S	
● blau / blue	90	200	20	12.7	13	10 m	E 2185/13/10/B	
● rot / red							E 2185/13/10/R	
● schwarz / black							E 2185/13/10/S	
● blau / blue							40 m	E 2185/13/40/B
● rot / red								E 2185/13/40/R
● schwarz / black	E 2185/13/40/S							

Außenmantel abriebfest und ölbeständig
Outer layer is resistant against oil and abrasion

i Weitere Informationen finden Sie im Informationsteil.
You can find more information in the information section.

