


E 21949

 



Schlauchklemme aus Edelstahl

Hose clamp from stainless steel

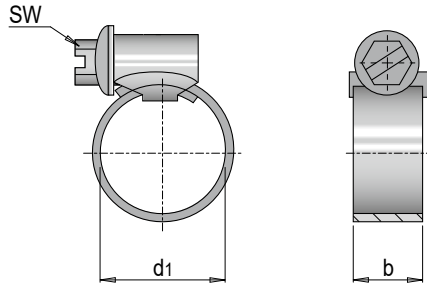

Mat.: Edelstahl (W5)
stainless steel (W5)

SW	Nm max.	b	d	d1	 Stk. / VPE Pcs. / PU	Nr. / No.
6	1.5	8	8-13	12	10	E 21949/12
7	2	9	8-17	16		E 21949/16
			12-22	22		E 21949/22
	3		16-26	25		E 21949/25
			20-33	32		E 21949/32
			25-41	40		E 21949/40

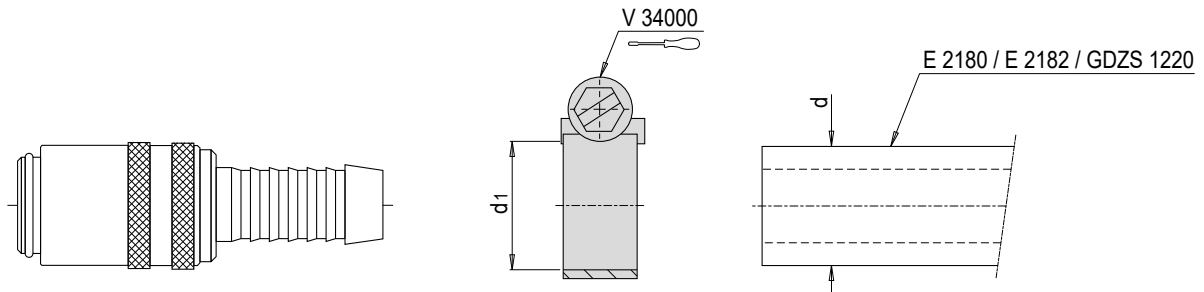

VERWENDUNGSEMPFEHLUNG SCHLÄUCHE:

HOSES RECOMMENDED FOR USE:

Nr./No.	E 2180	E 2182	GDZS 1220
E 21949/12			GDZS 1220/6 (d 12)
E 21949/16	E 2180/ 9 (d 16.5)	E 2182/ 9 (d 16)	GDZS 1220/9 (d 15)
E 21949/22		E 2182/13 (d 19)	
E 21949/25	E 2180/13 (d 21.5)		
E 21949/32	E 2180/19 (d 27)		