




E 220..



## Kuplung mit Schlauchtülle


Hose coupler

-  200°C
-  150°C
- PN** 15 bar

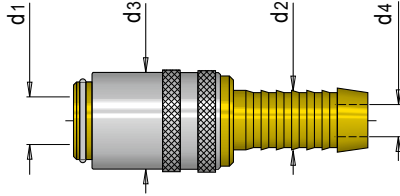

Messing  
Brass

Edelstahl  
Stainless steel

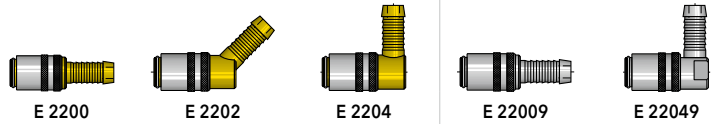

Mat.: 2.0401 (CuZn)

Mat.: 1.4305



d3	d4	d1	d2	Nr. / No.	Nr. / No.	Nr. / No.	Nr. / No.	Nr. / No.
17	6	9	9	E 2200/ 9/ 9	E 2202/ 9/ 9	E 2204/ 9/ 9	E 22009/ 9/ 9	E 22049/ 9/ 9
22	9	13	13	E 2200/13/13	E 2202/13/13	E 2204/13/13	E 22009/13/13	E 22049/13/13
31	13	19	19	E 2200/19/19	E 2202/19/19	E 2204/19/19		

**i** Weitere Maße finden Sie im Webshop. Weitere Informationen finden Sie im Informationsteil.  
For more dimensions visit the web shop. You can find more information in the information section.