

E 222..



## Sicherheitskupplung mit Außengewinde

Safety coupler with external thread



Safety



Oil

220°C



Water

180°C




PN

15 bar



verriegelt/locked

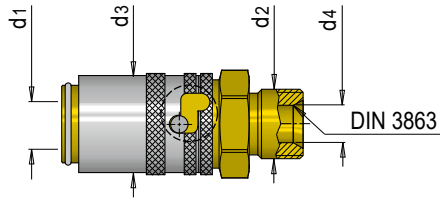

Messing  
Brass

Edelstahl  
Stainless steel



E 22206



E 22226



E 22246



E 22208



E 22248

Mat.: 2.0401 (CuZn)

Mat.: 1.4305



| d3 | d4 | d1 | d2        | Nr. / No.      | Nr. / No.      | Nr. / No.      | Nr. / No.      | Nr. / No.      |
|----|----|----|-----------|----------------|----------------|----------------|----------------|----------------|
| 17 | 6  | 9  | M14 x 1,5 | E 22206/ 9/14  | E 22226/ 9/14  | E 22246/ 9/14  | E 22208/ 9/14  | E 22248/ 9/14  |
|    |    |    | G 1/4"    | E 22206/ 9/1/4 | E 22226/ 9/1/4 | E 22246/ 9/1/4 | E 22208/ 9/1/4 | E 22248/ 9/1/4 |
| 22 | 9  | 13 | M16 x 1,5 | E 22206/13/16  | E 22226/13/16  | E 22246/13/16  | E 22208/13/16  | E 22248/13/16  |
|    |    |    | G 3/8"    | E 22206/13/3/8 | E 22226/13/3/8 | E 22246/13/3/8 | E 22208/13/3/8 | E 22248/13/3/8 |



Weitere Maße finden Sie im Webshop. Weitere Informationen finden Sie im Informationsteil.

For more dimensions visit the web shop. You can find more information in the information section.