

E 2252



 
Brücke, steckbar, mit Kupplungen

Bridge, plug-in type, with couplers


200°C

150°C

PN 15 bar





Mat.: 2.0401 (CuZn)

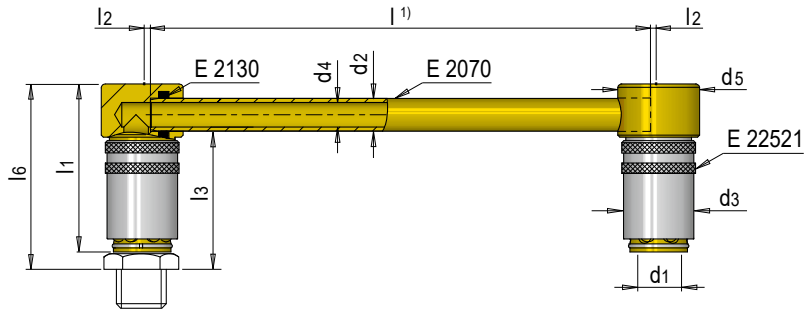

2x E 2130/.. x ..	l1	d2	l2	d3	l3	l6	d4	d5	d1	l ¹⁾	Ventil / Valve	Nr. / No.
E 2130/ 8 x2	43	8	2	17	34	47	6	20	9	250	-	E 2252/ 9/250
										500		E 2252/ 9/500
E 2130/ 10 x2,4	53	10	2	22	42	57	8	26	13	250	-	E 2252/13/250
										500		E 2252/13/500
E 2130/ 8 x2	43	8	2	17	34	47	6	20	9	250	V	E 2252/ 9/250 V
										500		E 2252/ 9/500 V
E 2130/ 10 x2,4	53	10	2	22	42	57	8	26	13	250	-	E 2252/13/250 V
										500		E 2252/13/500 V

1) l: Lieferlänge - kundenseitig kürzen und Fasse anbringen / l: Standard length of the product supplied - shortening and chamfering to be done by the customer

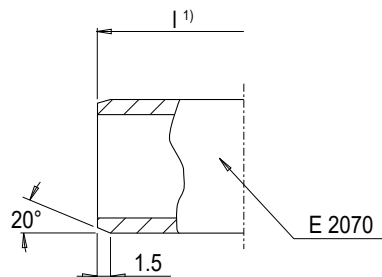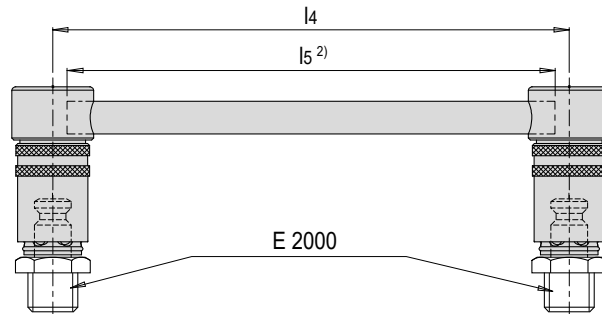

2) l5: $l5 = (l4 - 5 \text{ mm}) \pm 0.5$