

E 2480





Zykluszähler mechanisch


Mechanical cycle counter

» nicht rückstellbar


» not resettable

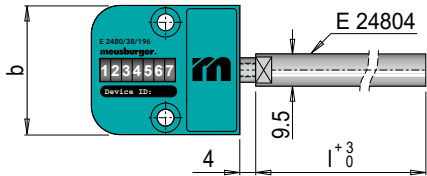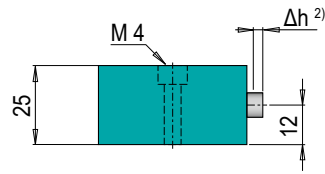


E 2480/38/196

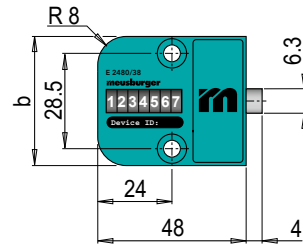

E 2480/38

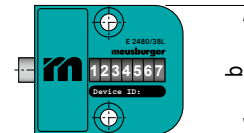

E 2480/38L

 


t max. = 120°C

b	l ¹⁾	Nr. / No.
38	-	E 2480/38
	196	E 2480/38L
		E 2480/38/196


1) l: Lieferlänge - kundenseitig kürzen (Maß "s") und Fasse anbringen / l: Standard length of the product supplied - shortening (dimension "s") and chamfering to be done by the customer

2) Δh: Schaltweg min 3,7mm / Δh: Contact travel not less than 3.7mm

E 2480/38/196

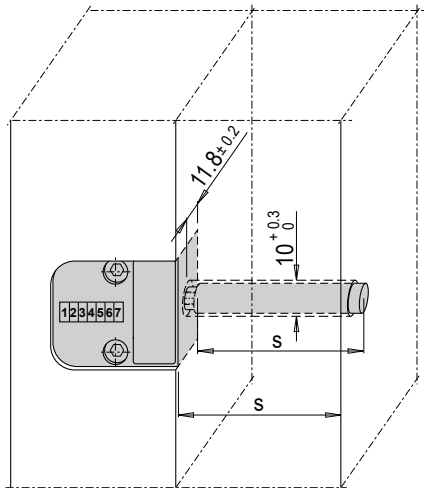

E 2480/38

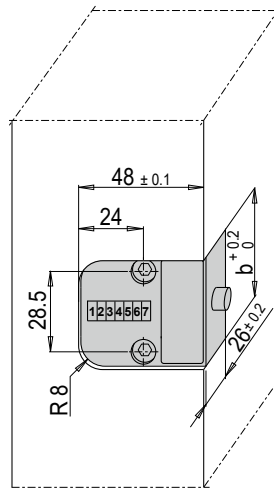

E 2480/38L

