

E 2500..



Verschlussnippel, leckagearm

Shut-off fitting, low-leakage



Oil

200°C (HT 220°C)




Water

150°C (HT 180°C)

PN

35 bar

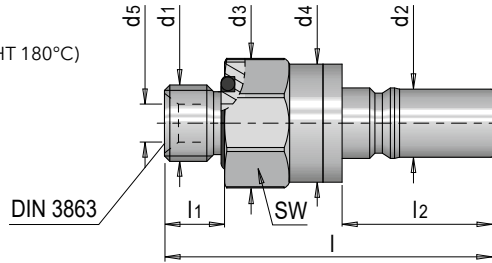

HT

Standard  
Standard

Hochtemperatur  
High temperature



E 2500



E 2500 HT

Mat.: Messing vernickelt, FKM /  
Brass, nickel-plated / FKM



SW	l	l1	l2	d2	d3	d4	d5	Typ / Type	DN	d1	Nr. / No.	Nr. / No.
22	60	11	27.5	12.5	25	21.6	7	9	6	M14x1,5	E 2500/ 6/ 14	E 2500 HT/ 6/ 14
										G 1/4"	E 2500/ 6/1/4	E 2500 HT/ 6/1/4
27	63.4	11	37.4	17	30	26.5	9	13	9	M16x1,5	E 2500/ 9/ 16	E 2500 HT/ 9/ 16
							10			G 3/8"	E 2500/ 9/3/8	E 2500 HT/ 9/3/8

