


E 27421



Kabelverschraubung

Cable gland

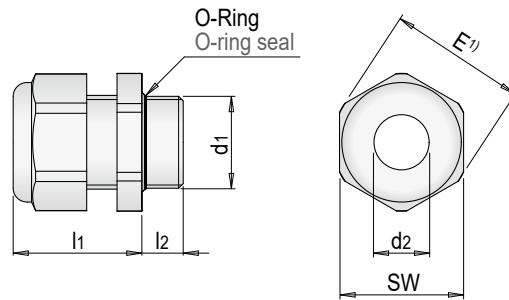

Mat.: Kunststoff PA / plastic PA

Schutzart / protection class IP68

t max. = 100°C

E ¹⁾	SW	Nm ²⁾	l1	l2	d1	d2 ³⁾	Nr. / No.
26.5	24	4.5	27	9	M20x1.5	5-9	E 27421/20/ 5
30	27	5	28	11	M25x1.5	10-14	E 27421/20/10
36.5	33		31			9-16	E 27421/25/ 9
						13-18	E 27421/25/13
47	42	6.5	39	11.5	M32x1.5	13-20	E 27421/32/13
						18-25	E 27421/32/18

1) E: Eckmaß / E: Width across corners

2) Nm: Anzugsdrehmoment / Nm: Tightening torque

3) d2: Klemmbereich / d2: Clamping range

