


E 2766



Kabelhalter magnetisch

Cable retainer, magnetic

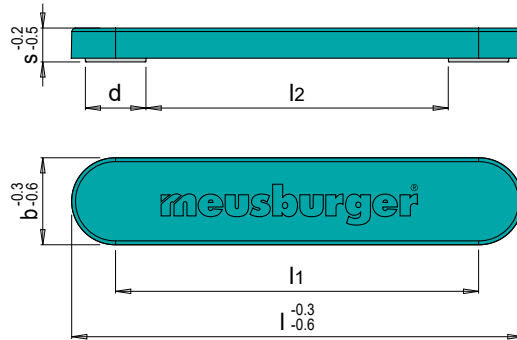

Mat.: PA+GF / Neodymmagnet
PA+GF / Neodymium magnet

t max. = 150°C

b	d	s	l1	l2	l	Stk. / VPE / Pcs. / PU	Nr. / No.
12	8	5	28	20	40	10	E 2766/40
			48	40	60		E 2766/60

