


E 28650



Winkelstück 90° mit Standardtülle

Hose nozzle 90° with standard spout

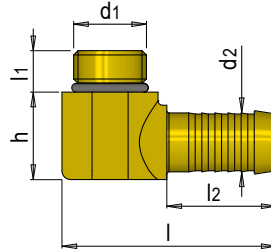

Dichtungen: FKM  
Sealings: FKM

t max = 150°C  
p max = 16 bar

| h  | l    | l1  | l2   | d1    | d2 | Nr. / No.       |
|----|------|-----|------|-------|----|-----------------|
| 20 | 46.5 | 9.5 | 22.5 | G3/8" | 9  | E 28650/3/8/B 9 |
|    | 49   |     | 25   |       | 13 | E 28650/3/8/B13 |

