


E 3142



Flachführungsleiste einseitig, wartungsfrei

One-sided self-lubricating flat guiding rail

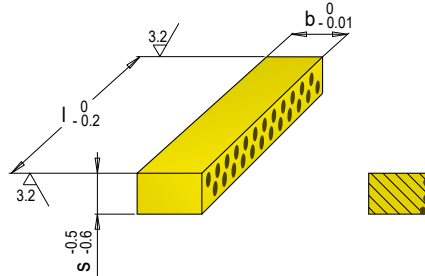


0.8/

Mat.: 2.0598

≈ 180 HB / Graphit / graphite

t max. = 200°C

b	s	l	Nr. / No.
16	6	40	E 3142/16/ 6/ 40
		50	E 3142/16/ 6/ 50
		63	E 3142/16/ 6/ 63
		80	E 3142/16/ 6/ 80
16	8	50	E 3142/16/ 8/ 50
		63	E 3142/16/ 8/ 63
		80	E 3142/16/ 8/ 80
		100	E 3142/16/ 8/100
20	12	63	E 3142/20/12/ 63
		80	E 3142/20/12/ 80
		100	E 3142/20/12/100
		125	E 3142/20/12/125
20	16	80	E 3142/20/16/ 80
		100	E 3142/20/16/100
		125	E 3142/20/16/125
		160	E 3142/20/16/160
25	22	100	E 3142/25/22/100
		125	E 3142/25/22/125
		160	E 3142/25/22/160
		200	E 3142/25/22/200
25	30	125	E 3142/25/30/125
		160	E 3142/25/30/160
		200	E 3142/25/30/200
		250	E 3142/25/30/250
32	38	160	E 3142/32/38/160
		200	E 3142/32/38/200
		250	E 3142/32/38/250
		315	E 3142/32/38/315

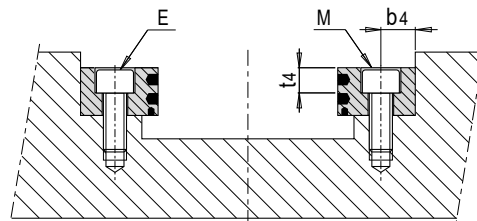

b	E	M	b4	t4
16	E 1226	M 5	6	4.5
20	E 1200	M 6	9	7
25	E 1200	M 8	11	9
32	E 1200	M10	14	11