


E 3360





Kompaktschiebereinheit

Compact slide unit

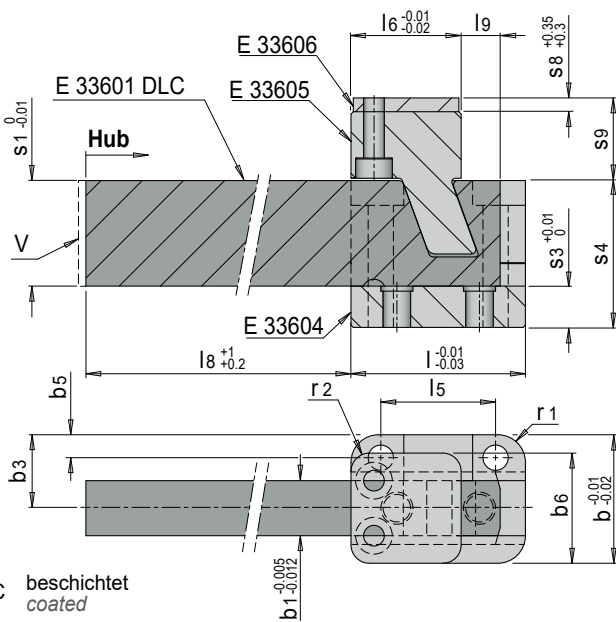

Typ A

Typ B

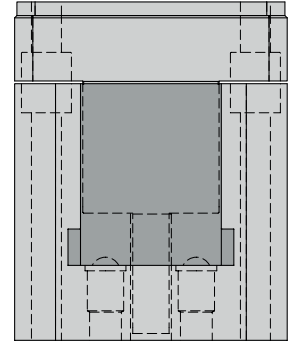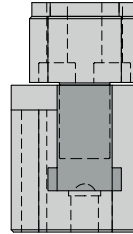

1(2) E 1265



Typ / Type ¹⁾	b	l	b3	r1	s3	b5	s4	l5	b6	l6	r2	l8	s8 ²⁾	l9	s9	s1	b1	Hub / Stroke	Nr. / No.
A	28	38	16	6	9	4	32	25	24	24	5	81	3	8.5	18	23	12	4.9	E 3360/23/12/ 4,9
A	42	50	25	7	12	7	42	34	34	32	6	105	3	10.5	18	30	22	6.9	E 3360/30/22/ 6,9
B	60	68	30	9	17	46	57	60	60	45	7	131	3	5	18	40	31	17.4	E 3360/40/31/17,4

1) Typ A: E 33604 kann um 180° verdreht eingebaut werden / Typ A: E 33604 can be installed rotated by 180°

2) s8: mit Zugabe zum Abstimmen / s8: With allowance for adjusting

3) V: Vorspannung / V: Preload

s1	d5	b7	d7	l7
23	M4	12	M4	19
30	M6	20	M6	25
40	M6	46	M6	31

VORSpannung PRELOAD

V ³⁾	s8
0.02	3.055
0.04	3.11
0.06	3.165

Typ A¹⁾

Typ B

