 




E 33604

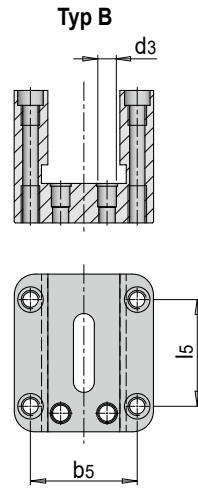

Schieberführung

Slide guide

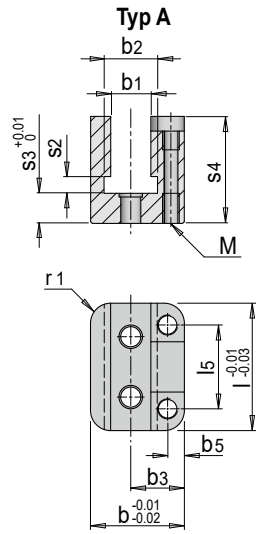

Mat.: 1.2363 ≈ 60 HRC

Typ / Type	b	l	r1	b2	s2	b3	d3	s3	s4	b5	M	d5	l5	b1	Nr. / No.
A	28	38	6	16.5	5	16	6	9	32	4	M 5	M 4	25	12	E 33604/12
A	42	50	7	26	5	25	8	12	42	7	M 8	M 6	34	22	E 33604/22
B	60	68	9	37	8	30	8	17	57	46	M 8	M 6	46	31	E 33604/31

