


E 5213



Kugelkäfig

Ball cage

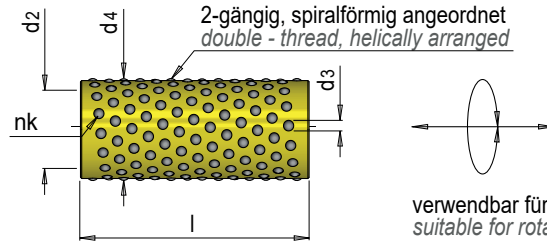

Mat.: 1.3505 / Messing/brass

d4	d3	nk ¹⁾	d2	l	Nr. / No.
6	1	24	4	10	E 5213/ 4 x 10
		36		15	E 5213/ 4 x 15
		54		20	E 5213/ 4 x 20
		68		25	E 5213/ 4 x 25
7	1	32	5	10	E 5213/ 5 x 10
		48		15	E 5213/ 5 x 15
		72		20	E 5213/ 5 x 20
		88		25	E 5213/ 5 x 25
		104		30	E 5213/ 5 x 30
9	1.5	48	6	15	E 5213/ 6 x 15
		56		20	E 5213/ 6 x 20
		72		25	E 5213/ 6 x 25
		88		30	E 5213/ 6 x 30
11	1.5	48	8	15	E 5213/ 8 x 15
		64		20	E 5213/ 8 x 20
		72		25	E 5213/ 8 x 25
		88		30	E 5213/ 8 x 30
		104		36	E 5213/ 8 x 36
		124		45	E 5213/ 8 x 45
14	2	40	10	15	E 5213/10 x 15
		56		20	E 5213/10 x 20
		72		25	E 5213/10 x 25
		88		30	E 5213/10 x 30
		104		36	E 5213/10 x 36
		128		45	E 5213/10 x 45
16	2	48	12	15	E 5213/12 x 15
		72		20	E 5213/12 x 20
		84		25	E 5213/12 x 25
		114		30	E 5213/12 x 30
		132		36	E 5213/12 x 36
		162		45	E 5213/12 x 45
		204		56	E 5213/12 x 56
		264		71	E 5213/12 x 71
22	3	40	16	20	E 5213/16 x 20
		68		30	E 5213/16 x 30
		88		36	E 5213/16 x 36
		112		45	E 5213/16 x 45
		140		56	E 5213/16 x 56
25	3	96	19	30	E 5213/19 x 30
		120		36	E 5213/19 x 36
		152		45	E 5213/19 x 45
		200		56	E 5213/19 x 56
		264		71	E 5213/19 x 71

1) nk: Anzahl Stahlkugeln / nk: number of steel balls

