


E 55602



Schneidstempel mit zylindrischem Kopf, mit Abdrückstift

Cutting punch with cylindrical head, with ejector

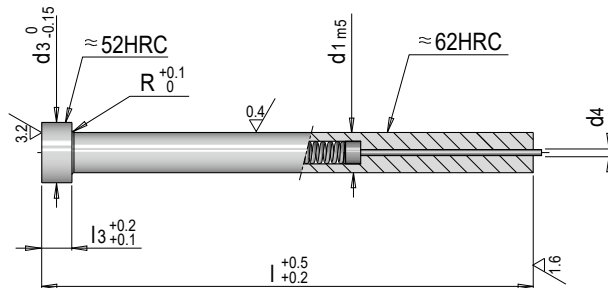

Mat.: 1.3344 PM (PM 23)

≈ DIN ISO 8020
Form E

d4	R	l3	d3	d1	l	Nr./No.
0.43	0.3	5	8	5	63	E 55602/ 5 x 63
					71	E 55602/ 5 x 71
					80	E 55602/ 5 x 80
					100	E 55602/ 5 x 100
0.68			9	6	63	E 55602/ 6 x 63
					71	E 55602/ 6 x 71
					80	E 55602/ 6 x 80
1.04			11	8	100	E 55602/ 6 x 100
					63	E 55602/ 8 x 63
					71	E 55602/ 8 x 71
					80	E 55602/ 8 x 80
1.47	0.4		13	10	100	E 55602/ 8 x 100
					63	E 55602/10 x 63
					71	E 55602/10 x 71
					80	E 55602/10 x 80
					100	E 55602/10 x 100
					71	E 55602/13 x 71
			16	13	80	E 55602/13 x 80
					100	E 55602/13 x 100
					80	E 55602/16 x 80
					100	E 55602/16 x 100



Abgesetzte Ausführungen und Beschichtungen über den Konfigurator in den Meusbürger Shops wählbar
Offset versions and coatings selectable via the configurator in the Meusbürger shops