


E 5810



## Stempelhalteplatte dreieckig für Schnellwechsel-Schneidstempel, schwere Ausführung

Triangular punch retainer plate for ball-lock cutting punches, heavy duty

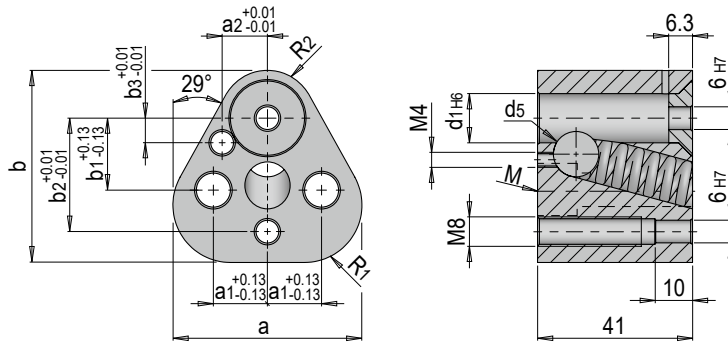

2 x E 1302/6x20



2 x E 1200



1 x E 1230/4x20

2 x E 1230/8x 8



≈ DIN ISO 11900-3  
Form E

Mat.: 1.6523 ≈ 55 HRC

a	b	a1	b1	R1	a2	b2	R2	b3	d5	M	d1	Nr. / No.
43.7	44.5	11,1	19	12	9	26.925	9.5	7.5	10	M 8 x 45	10	E 5810/10
50	50.8	14,3		15.2	12	29.97	12.7	6.5	12		13	E 5810/13
53.2	54	15,9		16.8	13.5	31.75	14.3	6	16		E 5810/16	
59.5	60.3	17,5		20	16.5	33.53	17.5	5	20		E 5810/20	
69.1	69.9	19,8	23.8	24.7	22	40.64	22.2	7	10	M10 x 50	25	E 5810/25
										M12 x 50	32	E 5810/32

