


**E 6700**



**Temperatursensor mit Bajonettverschluss**

*Thermocouple with bayonet fitting*

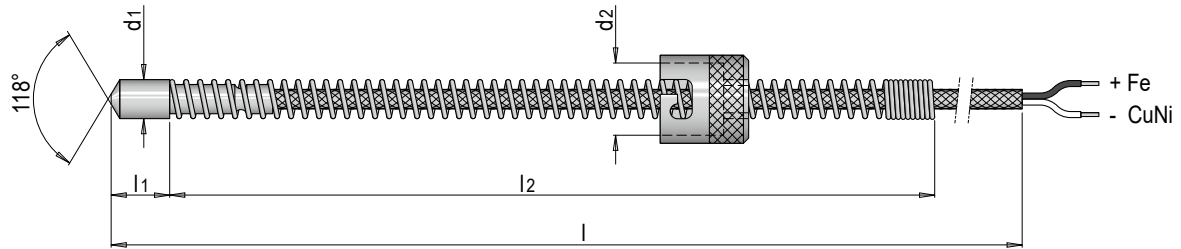

Thermoelement Typ J (Fe-CuNi DIN EN 60584, Kl. 1)  
Thermocouple type J (Fe-CuNi DIN EN 60584, class 1)

t max. = 400°C

l1	l2	d1	d2	l	Nr. / No.
12	195	6	12	2000	E 6700/ 6/12/2000
		8			E 6700/ 8/12/2000

Thermospannung / Thermoelectric voltage	Fe-CuNi DIN EN 60584, Kl. 1 (J) / Fe-CuNi DIN EN 60584, class 1 (J)
Messstelle / Measuring point	eingeschweißt / welded in
Fühlerspitze / Probe tip	Edelstahl / stainless steel
Thermoleitung / Thermo line	2 x 0,35 mm <sup>2</sup>
Adern / Cores	mit Glasseide umlegt / wrapped with glass fibre
Panzergeflecht / Wire braid	Edelstahl / stainless steel
Druckfeder / Compression spring	Edelstahl / stainless steel
Bajonettkappe / Bayonet cap	Ms 58 vernickelt / nickel-plated brass Ms 58

