


E 6704



Mantel-Tempersensoren

Mineral-insulated thermocouple

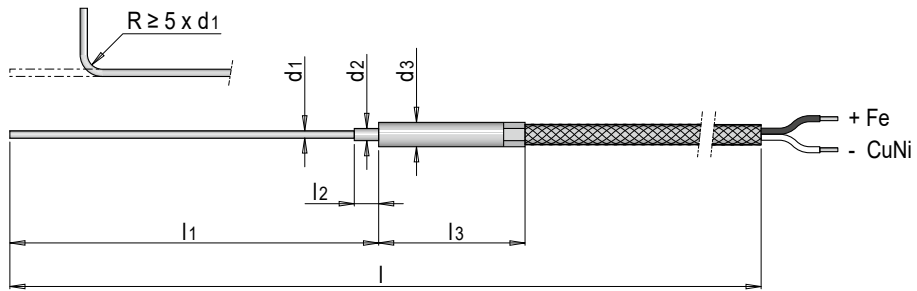

Thermoelement Typ J (Fe-CuNi DIN EN 60584, Kl. 1)
 Thermocouple type J (Fe-CuNi DIN EN 60584, class 1)

t max. = 400°C

d2	l2	d3	l3	d1	l1	l	Nr. / No.
2.5	5	5	30	1.5	100	2000	E 6704/ 1,5/100/2000
					150		E 6704/ 1,5/150/2000
					300		E 6704/ 1,5/300/2000

Thermospannung / Thermoelectric voltage	Fe-CuNi DIN EN 60584, Kl. 1 (J) / Fe-CuNi DIN EN 60584, class 1 (J)
Messstelle / Measuring point	isoliert / insulated
Mantelwerkstoff / Sheath material	Edelstahl / stainless steel
Thermoleitung / Thermo line	2 x 0,35 mm ²
Adern / Cores	mit Glasseide umlegt / wrapped with glass fibre
Panzergeflecht / Wire braid	Edelstahl / stainless steel

