


E 7451



Kunststoffschlauch PU-H

Flexible plastic tubing PU-H

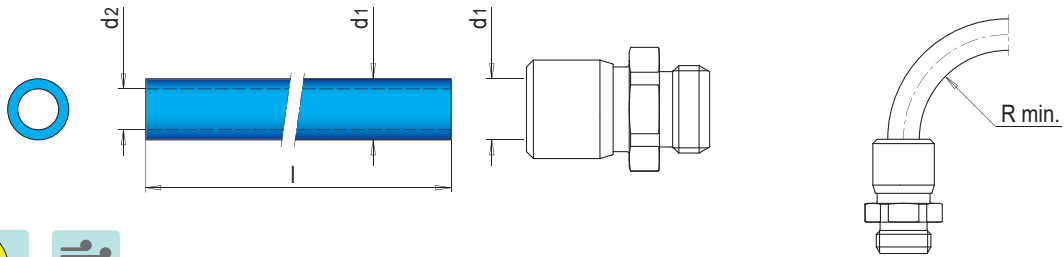

Mat.: PUR, hydrolysebeständig / hydrolysis resistant PUR

t max = 60°C

Farbe / Colour	p max./20°C [bar]	p max./60°C [bar]	R min.	d1	d2	l	Nr. / No.
● blau / blue	14	6	15	6	4	10 m	E 7451/ 6x 4 /10/B
						50 m	E 7451/ 6x 4 /50/B
● rot / red	14	6	15	6	4	10 m	E 7451/ 6x 4 /10/R
						50 m	E 7451/ 6x 4 /50/R
● blau / blue	10	6	25	8	5.5	10 m	E 7451/ 8x 5,5/10/B
						50 m	E 7451/ 8x 5,5/50/B
● rot / red	10	6	25	8	5.5	10 m	E 7451/ 8x 5,5/10/R
						50 m	E 7451/ 8x 5,5/50/R
● blau / blue	10	6	40	10	7	10 m	E 7451/10x 7 /10/B
						50 m	E 7451/10x 7 /50/B
● rot / red	10	6	40	10	7	10 m	E 7451/10x 7 /10/R
						50 m	E 7451/10x 7 /50/R
● blau / blue	14	8	35	12	8	10 m	E 7451/12x 8 /10/B
						50 m	E 7451/12x 8 /50/B
● rot / red	14	8	35	12	8	10 m	E 7451/12x 8 /10/R
						50 m	E 7451/12x 8 /50/R
● blau / blue	12	6	55	16	11	10 m	E 7451/16x11 /10/B
						10 m	E 7451/16x11 /10/R